


FBXLCUC11

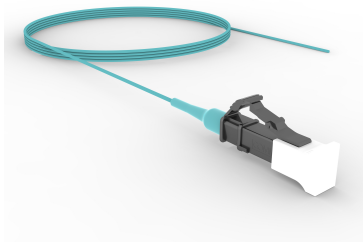

OM4 LC/UPC to Unconnectorized, Fiber Pigtail, 0.9 mm SBJ

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Fiber pigtail, unjacketed
Product Brand	SYSTIMAX InstaPATCH® 360
Ordering Note	Minimum length may vary based on cable configuration

General Specifications


Color, boot A	Aqua
Color, connector A	Black
Interface, Connector A	LC/UPC
Jacket Color	Aqua
Total Fibers, quantity	1
Transmission Standards	TIA/EIA-568-C.3

Dimensions

Cable Assembly Length Range (m)	1 – 20
Cable Assembly Length Range (ft)	1 – 66

Ordering Tree

FBXLCUC11

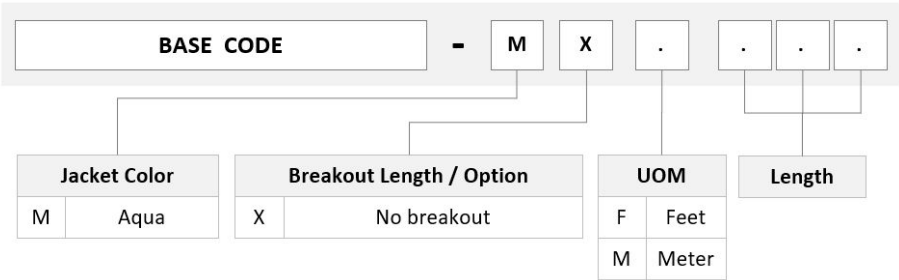

Mechanical Specifications

Cable Retention Strength, maximum 2.00 lb @ 90 ° | 5.00 lb @ 0 °

Optical Specifications

Fiber Mode Multimode
Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space Low Smoke Zero Halogen (LSZH)

Packaging and Weights

Packaging quantity 2

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant



Included Products

FBXLCUC11

- | | | |
|-------------------|---|---|
| 760010603 | – | Fiber Indoor Cable, LazrSPEED® 0.9 mm Low Smoke Zero Halogen Reinforced Buffered, 1 |
| N-001-RF-5K-F09AQ | | fiber, Multimode OM4, Gel-free, Feet jacket marking, Aqua jacket color |
| 860657284 | – | LC/UPC Connector, Multimode, Aqua |