



XAGA® 1000 Copper Closure, pressurized, heat shrink, 500 mm sheath opening, 92 mm splice bundle diameter

- High performance heat-shrinkable closure for both maintenance and new constructions
- Suitable for use with all standard copper connector systems
- Full range of closures to suit all copper cable sizes

Product Classification

Product Type	Pressurized heat shrink closure
Product Series	XAGA 1000
Regional Availability	EMEA
Product Brand	XAGA®


General Specifications

Application	For use with Polyethylene and metal jacketed cables
Branch-off Clip	To be ordered separately
Cable Capacity, maximum	4
Color	Black
Includes	Abrasive strip Aluminum closing strip Aluminum foil Cleaning tissues Flexible stainless steel channels Heatshrinkable sleeve Metal canister Shield continuity wire Underclips Valve hardware
Package, quantity	1
Packaging Type	Bag Carton
Single Cable Diameter, minimum	30.00 mm 1.18 in
Splice Bundle Diameter, maximum	92.00 mm 3.62 in

Dimensions

Sheet Opening, nominal	500.00 mm 19.69 in
-------------------------------	----------------------

Dimension Drawing

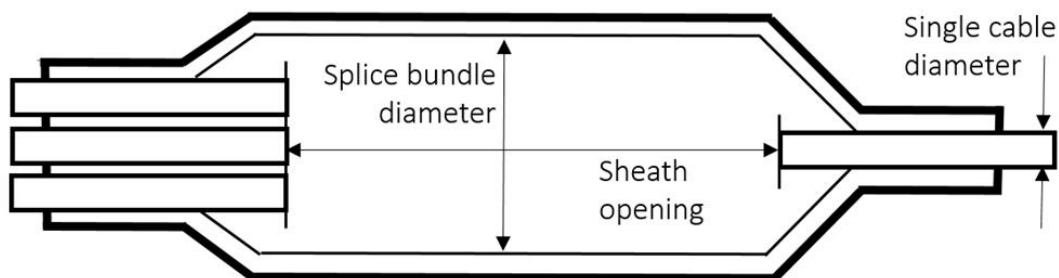

Dimension Drawing Used as an image placeholder

Mechanical Specifications

Cable Sealing Type	Hotmelt adhesive
Closure Style	In-line
Material Type	Fiber-reinforced multi-layer sealing sleeve
Mount Type	Duct Manhole
Splice Protection Type	Metal canister with valve

Environmental Specifications

Environmental Space Aerial | Below ground | Buried

Regulatory Compliance/Certifications

Agency
RoHS 2011/65/EU

Classification
Compliant

