


Q-OFX-V

Fiber Frame, Cross-Connect Q-Frame

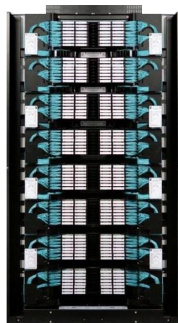

Product Classification

Product Series	Q Frame
Product Type	Frame
Regional Availability	Australia/New Zealand EMEA Latin America North America

Construction Materials

Finish	Powder coated
Material Type	Steel

Dimensions

Depth	608.00 mm 23.94 in
Height	2132.00 mm 83.94 in
Width	1034.00 mm 40.71 in

Environmental Specifications

Environmental Space	Indoor
Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Relative Humidity	5%–95%, non-condensing

General Specifications

Color	Black
Growth Configuration	Unloaded
Includes	Cable management
Package Quantity	1
Packaging Type	Crate Pallet

Mechanical Specifications

Access	Front Rear
---------------	--------------

Q-OFX-V

Regulatory Compliance/Certifications

Agency

RoHS 2011/65/EU

Classification

Compliant

