



XAGA® 1000 Copper Closure, pressurized, heat shrink, 250 mm sheath opening, 62 mm splice bundle diameter

- High performance heat-shrinkable closure for both maintenance and new constructions
- Suitable for use with all standard copper connector systems
- Full range of closures to suit all copper cable sizes

Product Classification

Product Type	Pressurized heat shrink closure
Product Series	XAGA 1000
Regional Availability	EMEA
Product Brand	XAGA®


General Specifications

Application	For use with Polyethylene and metal jacketed cables
Branch-off Clip	To be ordered separately
Cable Capacity, maximum	4
Color	Black
Includes	Abrasive strip Aluminum closing strip Aluminum foil Cleaning tissues Flexible stainless steel channels Heatshrinkable sleeve Metal canister Shield continuity wire Underclips Valve hardware
Package, quantity	1
Packaging Type	Bag Carton
Single Cable Diameter, minimum	15.00 mm 0.59 in
Splice Bundle Diameter, maximum	62.00 mm 2.44 in

Dimensions

Sheet Opening, nominal	250.00 mm 9.84 in
-------------------------------	---------------------

Dimension Drawing

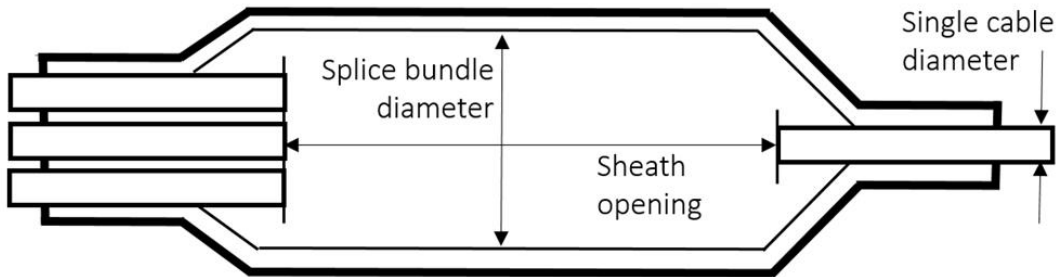

Dimension Drawing Used as an image placeholder

Mechanical Specifications

Cable Sealing Type	Hotmelt adhesive
Closure Style	In-line
Material Type	Fiber-reinforced multi-layer sealing sleeve
Mount Type	Duct Manhole
Splice Protection Type	Metal canister with valve

Environmental Specifications

Environmental Space Aerial | Below ground | Buried

Regulatory Compliance/Certifications

Agency
RoHS 2011/65/EU

Classification
Compliant

