



XAGA® 1000 Copper Closure, pressurized, heat shrink, 21 inch sheath opening, 4.8 inch splice bundle diameter

- Full range of closures to suit all copper cable sizes
- High performance heat-shrinkable closure for both maintenance and new constructions
- Suitable for use with all standard copper connector systems

Product Classification

Product Type	Pressurized heat shrink closure
Product Series	XAGA 1000
Regional Availability	Latin America North America
Product Brand	XAGA®


General Specifications

Application	For use with Polyethylene and metal jacketed cables
Branch-off Clip	To be ordered separately
Cable Capacity, maximum	4
Color	Black
Includes	Abrasive strip Aluminum closing strip Aluminum foil Cleaning tissues Flexible stainless steel channels Heatshrinkable sleeve Metal canister Shield continuity wire Underclips Valve hardware
Package, quantity	1
Packaging Type	Bag Carton
Single Cable Diameter, minimum	38.10 mm 1.50 in
Splice Bundle Diameter, maximum	4.80 mm 0.19 in

Dimensions

Sheet Opening, nominal	533.40 mm 21.00 in
-------------------------------	----------------------

Dimension Drawing

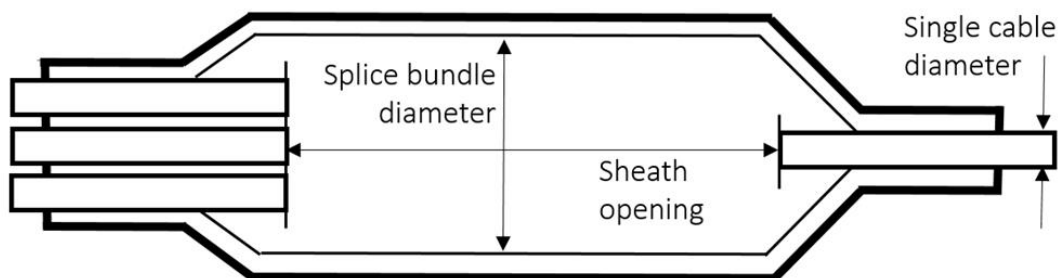

Dimension Drawing Used as an image placeholder

Mechanical Specifications

Cable Sealing Type	Hotmelt adhesive
Closure Style	In-line
Material Type	Fiber-reinforced multi-layer sealing sleeve
Mount Type	Duct Manhole
Splice Protection Type	Metal canister with valve

Environmental Specifications

Environmental Space Aerial | Below ground | Buried

Regulatory Compliance/Certifications

Agency
RoHS 2011/65/EU

Classification
Compliant

