



XAGA® 1650 Copper Closure, unpressurized, heat shrink, 37 inch sheath opening, 2.2 inch splice bundle diameter

- Full range of closures to suit all copper cable sizes
- High performance heat-shrinkable closure for both maintenance and new constructions
- Suitable for use with all standard copper connector systems

## Product Classification

<b>Product Type</b>	Unpressurized heat shrink closure
<b>Product Series</b>	XAGA 1650
<b>Regional Availability</b>	Latin America   North America
<b>Product Brand</b>	XAGA®


## General Specifications

<b>Application</b>	For use with Polyethylene and metal jacketed cables
<b>Branch-off Clip</b>	To be ordered separately
<b>Cable Capacity, maximum</b>	3
<b>Color</b>	Black
<b>Includes</b>	Abrasive strip   Aluminum closing strip   Aluminum foil   Cleaning tissues   Flexible stainless steel channels   Heatshrinkable sleeve   Metal canister   Shield continuity wire   Underclips   Valve hardware
<b>Package, quantity</b>	1
<b>Packaging Type</b>	Bag   Carton
<b>Single Cable Diameter, minimum</b>	12.19 mm   0.48 in
<b>Splice Bundle Diameter, maximum</b>	55.88 mm   2.20 in

## Dimensions

<b>Sheet Opening, nominal</b>	939.80 mm   37.00 in
-------------------------------	----------------------

## Dimension Drawing

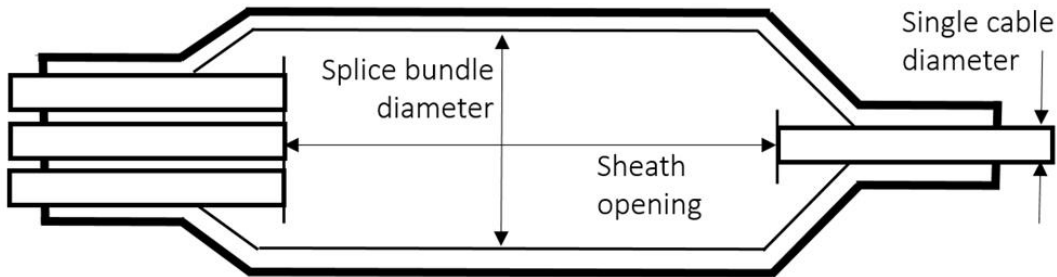

**Dimension Drawing**                      Used as an image placeholder

## Mechanical Specifications

<b>Cable Sealing Type</b>	Hotmelt adhesive
<b>Closure Style</b>	In-line
<b>Material Type</b>	Fiber-reinforced multi-layer sealing sleeve
<b>Mount Type</b>	Duct   Manhole
<b>Splice Protection Type</b>	Hygroscopic liner   Laminated cardboard liner

## Environmental Specifications

**Environmental Space**                      Aerial | Below ground | Buried

## Regulatory Compliance/Certifications

**Agency**  
RoHS 2011/65/EU

**Classification**  
Compliant

