



XAGA® 1650 Copper Closure, unpressurized, heat shrink, 21 inch sheath opening, 5.3 inch splice bundle diameter

- Full range of closures to suit all copper cable sizes
- High performance heat-shrinkable closure for both maintenance and new constructions
- Suitable for use with all standard copper connector systems

Product Classification

Product Type	Unpressurized heat shrink closure
Product Series	XAGA 1650
Regional Availability	Latin America North America
Product Brand	XAGA®


General Specifications

Application	For use with Polyethylene and metal jacketed cables
Branch-off Clip	To be ordered separately
Cable Capacity, maximum	3
Color	Black
Includes	Abrasive strip Aluminum closing strip Aluminum foil Cleaning tissues Flexible stainless steel channels Heatshrinkable sleeve Metal canister Shield continuity wire Underclips Valve hardware
Package, quantity	1
Packaging Type	Bag Carton
Single Cable Diameter, minimum	46.99 mm 1.85 in
Splice Bundle Diameter, maximum	134.62 mm 5.30 in

Dimensions

Sheet Opening, nominal	533.40 mm 21.00 in
-------------------------------	----------------------

Dimension Drawing

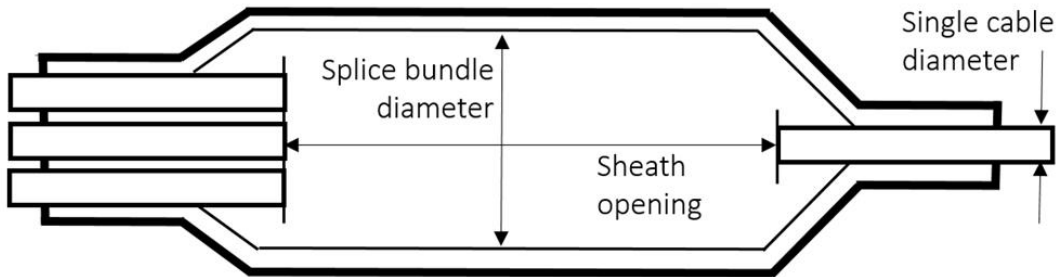

Dimension Drawing Used as an image placeholder

Mechanical Specifications

Cable Sealing Type	Hotmelt adhesive
Closure Style	In-line
Material Type	Fiber-reinforced multi-layer sealing sleeve
Mount Type	Duct Manhole
Splice Protection Type	Hygroscopic liner Laminated cardboard liner

Environmental Specifications

Environmental Space Aerial | Below ground | Buried

Regulatory Compliance/Certifications

Agency
RoHS 2011/65/EU

Classification
Compliant

