



XAGA® 500 Copper Closure, unpressurized, heat shrink, 240 mm sheath opening, 75 mm splice bundle diameter

- Full range of closures to suit all copper cable sizes
- High performance heat-shrinkable closure for both maintenance and new constructions
- Suitable for use with all standard copper connector systems

## Product Classification

<b>Product Type</b>	Unpressurized heat shrink closure
<b>Product Series</b>	XAGA 500
<b>Regional Availability</b>	EMEA
<b>Product Brand</b>	XAGA®


## General Specifications

<b>Application</b>	For use with Polyethylene and metal jacketed cables
<b>Branch-off Clip</b>	To be ordered separately
<b>Cable Capacity, maximum</b>	3
<b>Color</b>	Black
<b>Includes</b>	Abrasive strip   Aluminum closing strip   Aluminum foil   Cleaning tissues   Flexible stainless steel channels   Heatshrinkable sleeve   Metal canister   Shield continuity wire   Underclips   Valve hardware
<b>Package, quantity</b>	1
<b>Packaging Type</b>	Bag   Carton
<b>Single Cable Diameter, minimum</b>	15.00 mm   0.59 in
<b>Splice Bundle Diameter, maximum</b>	75.00 mm   2.95 in

## Dimensions

<b>Sheet Opening, nominal</b>	240.00 mm   9.45 in
-------------------------------	---------------------

## Dimension Drawing

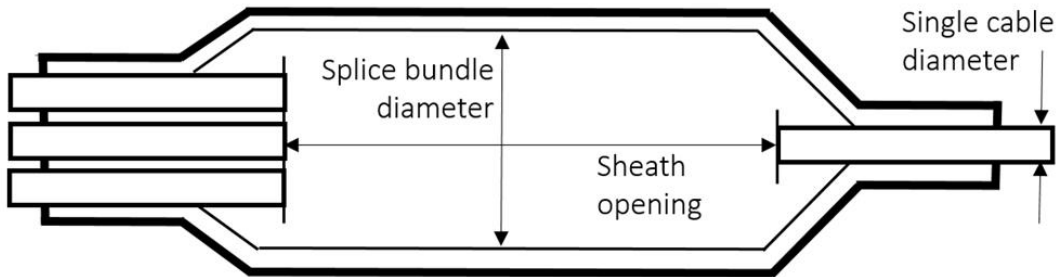

**Dimension Drawing**                      Used as an image placeholder

## Mechanical Specifications

<b>Cable Sealing Type</b>	Hotmelt adhesive
<b>Closure Style</b>	In-line
<b>Material Type</b>	Fiber-reinforced multi-layer sealing sleeve
<b>Mount Type</b>	Duct   Manhole
<b>Splice Protection Type</b>	Hygroscopic liner   Laminated cardboard liner

## Environmental Specifications

**Environmental Space**                      Aerial | Below ground | Buried

## Regulatory Compliance/Certifications

**Agency**  
RoHS 2011/65/EU

**Classification**  
Compliant

