



XAGA® 550 Copper Closure, unpressurized, heat shrink, 650 mm sheath opening, 75 mm splice bundle diameter

- Full range of closures to suit all copper cable sizes
- High performance heat-shrinkable closure for both maintenance and new constructions
- Suitable for use with all standard copper connector systems

Product Classification

Product Type	Unpressurized heat shrink closure
Product Series	XAGA 550
Regional Availability	EMEA
Product Brand	XAGA®


General Specifications

Application	For use with Polyethylene and metal jacketed cables
Branch-off Clip	To be ordered separately
Cable Capacity, maximum	3
Color	Black
Includes	Abrasive strip Aluminum closing strip Aluminum foil Cleaning tissues Flexible stainless steel channels Heatshrinkable sleeve Metal canister Shield continuity wire Underclips Valve hardware
Package, quantity	1
Packaging Type	Bag Carton
Single Cable Diameter, minimum	15.00 mm 0.59 in
Splice Bundle Diameter, maximum	75.00 mm 2.95 in

Dimensions

Sheet Opening, nominal	650.00 mm 25.59 in
-------------------------------	----------------------

Dimension Drawing

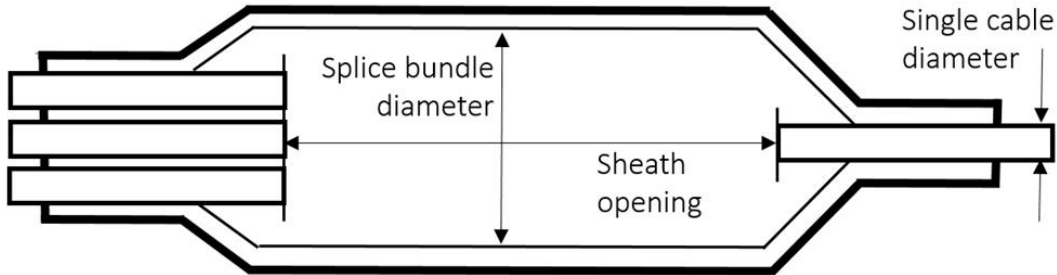

Dimension Drawing Used as an image placeholder

Mechanical Specifications

Cable Sealing Type	Hotmelt adhesive
Closure Style	In-line
Material Type	Fiber-reinforced multi-layer sealing sleeve
Mount Type	Duct Manhole
Splice Protection Type	Metal canister

Environmental Specifications

Environmental Space Aerial | Below ground | Buried

Regulatory Compliance/Certifications

Agency
RoHS 2011/65/EU

Classification
Compliant

