


FPP-12SU-60M

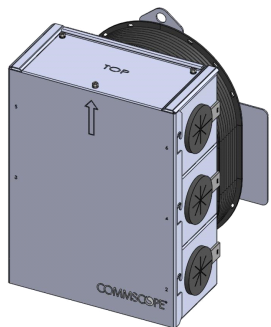

HELIAX® FiberFeed® Fiber Plug and Play 6 RRU Solution that will interface with Ericsson, Nokia, Huawei or ZTE RRU's, 60M

Product Classification

Portfolio	CommScope®
Brand	FiberFeed® HELIAX®
Product Type	Outdoor junction box
Regional Availability	Asia Australia/New Zealand EMEA Latin America North America

Construction Materials

Material Type	Aluminum
----------------------	----------

Dimensions

Depth	234.95 mm 9.25 in
Height	406.40 mm 16.00 in
Width	406.40 mm 16.00 in
Weight	11.30 kg 24.91 lb

Environmental Specifications

Environmental Space	Indoor Outdoor
Qualification Standards	IEC 60529:2001, IP67

General Specifications


Application	For use with Ericsson, Nokia, Huawei or ZTE remote radio units (RRU's)
Color	Gray
Includes	Mounting kit

Mechanical Specifications

Cable Entry Location	Side
Cable Entry, quantity, maximum, right	3
Cable Entry, quantity, maximum, top	3
Mount Type	Pipe, 76.2–101.6 mm (3.0–4.0 in) OD Wall

FPP-12SU-60M

Outline Drawing

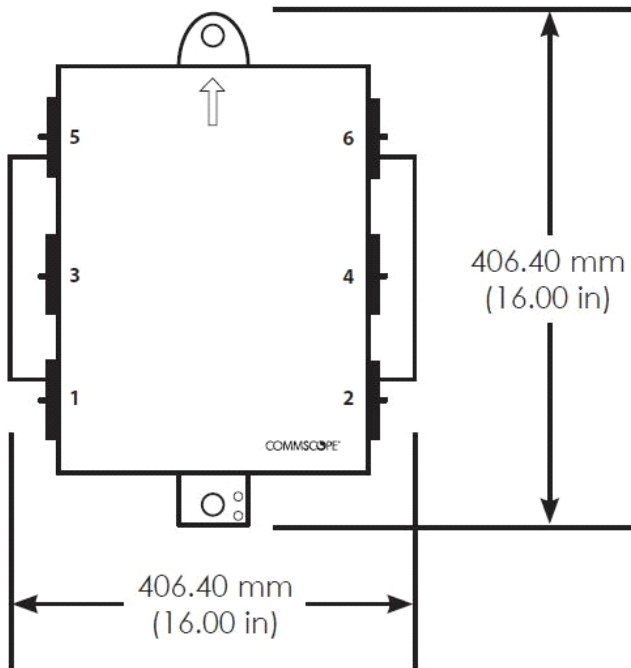

Regulatory Compliance/Certifications

Agency

ISO 9001:2015

Classification

Designed, manufactured and/or distributed under this quality management system

