


SYSTIMAX 360™ iPatch® G2 Fiber Panel with InstaPATCH 360 TeraSPEED Modules

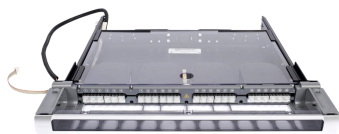

Product Classification

Portfolio	SYSTIMAX®
Brand	iPatch® SYSTIMAX 360™
Product Type	Fiber splice panel
Regional Availability	Asia Australia/New Zealand EMEA Latin America North America

Construction Materials

Fiber Mode	Singlemode
Material Type	Acrylonitrile butadiene styrene (ABS) Polycarbonate (PC)

Dimensions

Depth	355.60 mm 14.00 in
Height	44.45 mm 1.75 in
Width	482.60 mm 19.00 in
Weight	2.95 kg 6.50 lb

Environmental Specifications

Flammability Rating	UL 94 V-0
Operating Temperature	-5 °C to +50 °C (+23 °F to +122 °F)
Relative Humidity	Up to 95%, non-condensing
Safety Standard	Austel CE CSA UL
Storage Temperature	-40 °C to +70 °C (-40 °F to +158 °F)

General Specifications

Intelligence Type	iPatch® enabled
Rack Units	1.0
Shelf Movement	Sliding
Color	Black
Interface, front	LC
Package Quantity	1
Total Ports, quantity	24

Regulatory Compliance/Certifications

Agency

RoHS 2011/65/EU
ISO 9001:2015

Classification

Compliant
Designed, manufactured and/or distributed under this quality management system

