

Armored Grounding Kits Installation Guide

General

This installation guide provides guidelines for armored cable preparation, and procedures for proper installation of armored grounding KITS and Rack to Rack grounding KIT; these KITS are designed to be used in Data Centers / Central office.

Ordering information is listed below:

PART NUMBER	CATALOG NUM.	DESCRIPTION
760258219	CSAGK	ARMORED CABLE GROUNDING KIT .62"-1.03"
760258218	CSAGKX	ARMORED CABLE GROUNDING KIT .94"-1.50"
760258272	CSAGKR	RACK TO RACK GROUND KIT

How to Contact Us

To find out more about **CommScope** products, visit us on the web at <http://www.commscope.com/>

For technical assistance, customer service, or to report any missing/damaged parts, visit us at <http://www.commscope.com/SupportCenter>

Tools Required



- Gloves (latex and nitrile gloves for cut resistant)
- Caliper or tape measure
- 1/4" socket or nut driver
- Phillips screwdriver (PH3)
- Pen or marker
- Box Cutter

Cable preparation — Strip armored cable jacket, approx. 1.00 – 1.25 in.


1. Using marker or pen mark the 1.00-1.25 in.



2. Using cutter, strip armored cable jacket.



3. Verify that ground terminal makes good contact with non-jacketed armored cable.

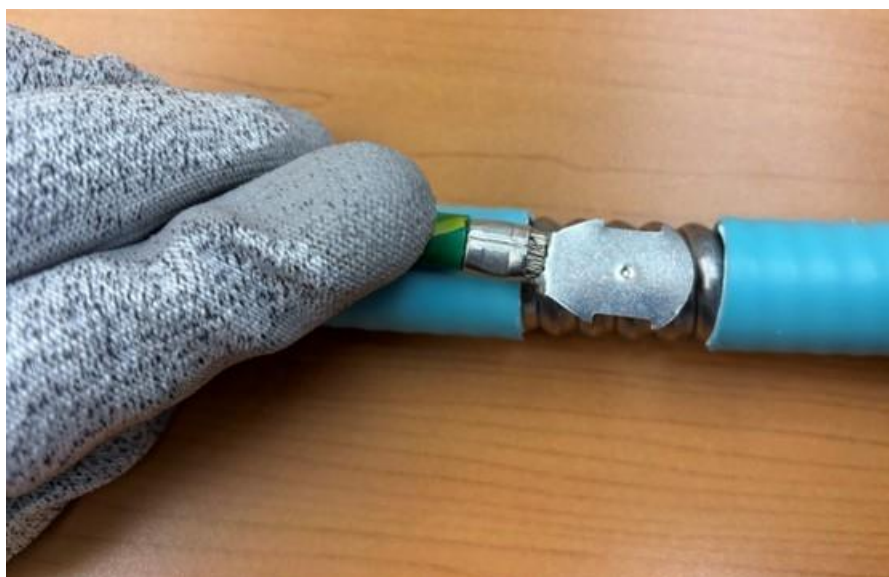

CSAGK: ARMORED CABLE GROUNDING KIT .62"-1.03"



CSAGK parts list:

- Armored cable ground 24in Length
- PP black cover CFNFR
- Worm-drive hose clamp 9/16" - 1 1/16"
- M6-1 PH, Paint cutting screw (2)
- 12-24 PH, Paint cutting screw (2)

CSAGK ARMORED CABLE GROUNDING KIT INSTALLATION

1. Insert hose clamp and align it using ground terminal slot guides.




- Using 1/4" socket or nut driver, tight hose clamp, torque at 14-16 in-lbs.



- Use insulation cover to protect and hides connection.



- Bond connection by screwing straight lug to rack using provided M6 or 12-24 screws, torque at 14-16 in-lbs.

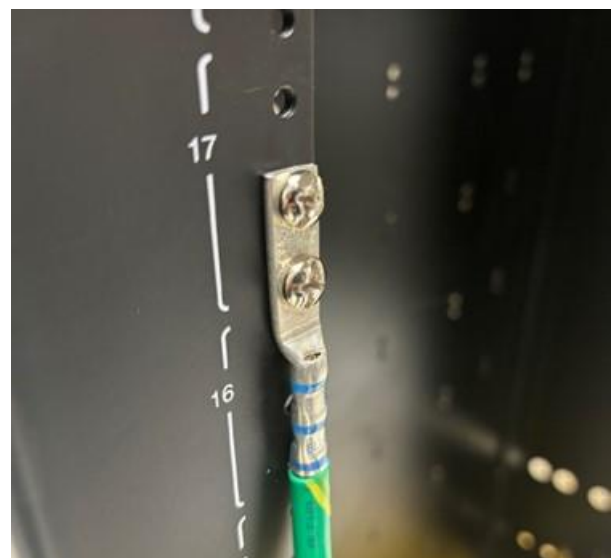

CSAGKX: ARMORED CABLE GROUNDING KIT .94"-1.50"



CSAGKX parts list:

- Armored cable ground 24in Length
- PP black cover CFRFR
- Worm-drive hose clamp 15/16" - 1 1/2"
- M6-1 PH, Paint cutting screw (2)
- 12-24 PH, Paint cutting screw (2)

CSAGKX ARMORED CABLE GROUNDING KIT INSTALLATION

1. Insert hose clamp and align it using ground terminal slot guides.




- Using 1/4" socket or nut driver, tight hose clamp, torque at 14-16 in-lbs.



- Use insulation cover to protect and hides connection.



- Bond connection by screwing straight lug to rack using provided M6 or 12-24 screws, torque at 14-16 in-lbs.

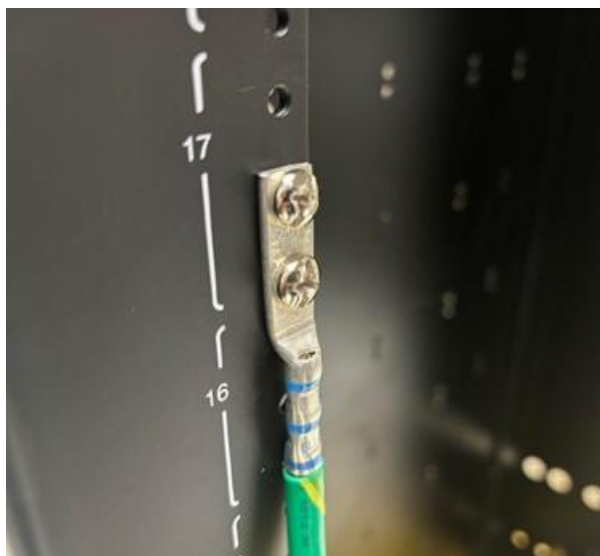

CSAGKR: RACK TO RACK GROUND KIT



CSAGKR parts list:

- Rack ground 6 AWG jumper 24in Length
- M6-1 PH, Paint cutting screw (4)
- 12-24 PH, Paint cutting screw (4)
-

CSAGKR RACK TO RACK GROUND KIT INSTALLATION

1. Bond jumper by screwing both ends of the straight lug to rack using provided M6 or 12-24 screws, torque at 14-16 in-lbs.

