


ARGRPLU7R

Base Product

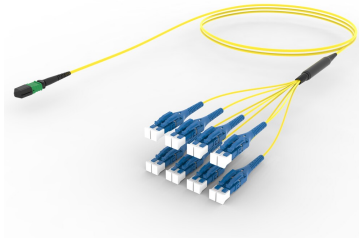

Ultra Low Loss (ULL) Singlemode, MPO16 (Non-Pinned) to LC Uniboot, Fiber Array Cable Assembly, 16-Fiber, Dual Rated (OFNR/LSZH), Method A

Product Classification

Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

Portfolio

CommScope®

Product Type

Fiber array cable assembly

Product Brand

Propel | SYSTIMAX ULL

Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative | For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

General Specifications


Connector A, quantity	1
Color, boot A	Black
Color, connector A	Green
Connector B, quantity	16
Color, boot B	Blue
Color, connector B	Black
Construction Type	Stranded
Furcation Color	Yellow
Interface, Connector A	MPO-16/APC Female
Interface, Connector B	LC/UPC
Interface Feature, connector B	Uniboot
Jacket Color	Yellow
Polarity	Method A
Fibers per Subunit, quantity	16
Total Fibers, quantity	16

ARGRPLU7R

Dimensions

Breakout Length	12 in 24 in 36 in 48 in 60 in 72 in
Cable Assembly Length Range (m)	1 – 304
Cable Assembly Length Range (ft)	2 – 999

Ordering Tree

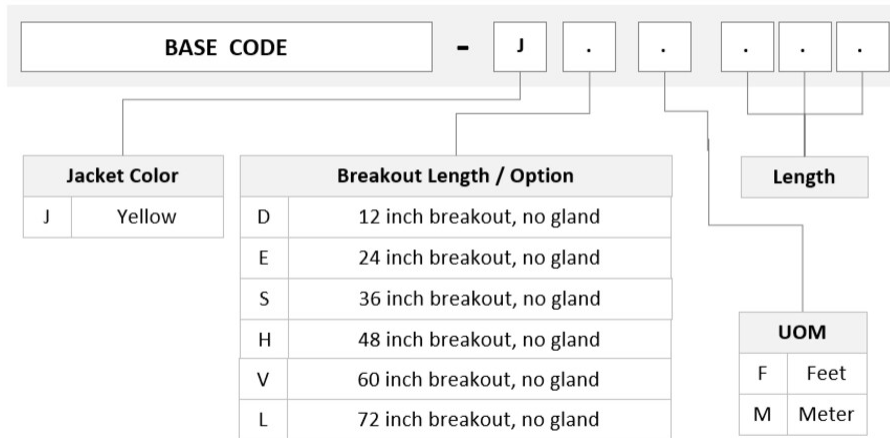

Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0 ° 4.40 lb @ 90 °
--	---------------------------------

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Dual Rated LSZH/Riser Indoor

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted

ARGRPLU7R

UK-ROHS

Compliant/Exempted



Included Products

- | | | |
|-----------------------------------|---|---|
| 760251072
N-016-MP-8G1-F30YL/D | - | Fiber indoor cable, TeraSPEED® Low Smoke Zero Halogen Riser for Light Duty MPO Patchcords, 16 fiber, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color, Dca flame rating |
| 860650412 | - | TeraSPEED® LC UniBoot 2.0MM UPC/LC UNIBOOT CONNECTOR KIT |
| 860658160 | - | LC/UPC Uniboot Connector, Singlemode, Blue |
| 860661407 | - | MPO16,ULL,FEMALE,SM,GREEN,3mm |