


# UJGMXMXCN

## Base Product

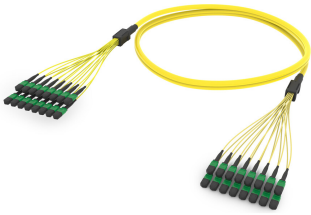

Ultra Low Loss Singlemode MPO12 Pinned to MPO12 Pinned 192-Fiber Pre-terminated Trunk Cable, Low Smoke Zero Halogen/Riser

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   Europe   Latin America   Middle East /Africa   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber trunk cable assembly
<b>Product Brand</b>	SYSTIMAX ULL
<b>Ordering Note</b>	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications

<b>Color, boot A</b>	Black
<b>Color, connector A</b>	Green
<b>Color, boot B</b>	Black
<b>Color, connector B</b>	Green
<b>Construction Type</b>	Stranded
<b>Furcation Color</b>	Yellow
<b>Interface, Connector A</b>	MPO-12/APC Male
<b>Interface Feature, connector A</b>	Angled
<b>Interface, Connector B</b>	MPO-12/APC Male
<b>Interface Feature, connector B</b>	Angled
<b>Jacket Color</b>	Yellow
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Fibers per Subunit, quantity</b>	12
<b>Total Fibers, quantity</b>	192

## Dimensions


<b>Cable Assembly Length Range (m)</b>	3 – 999
----------------------------------------	---------

# UJGMXMXCN

Cable Assembly Length Range (ft)

10 – 999

## Ordering Tree

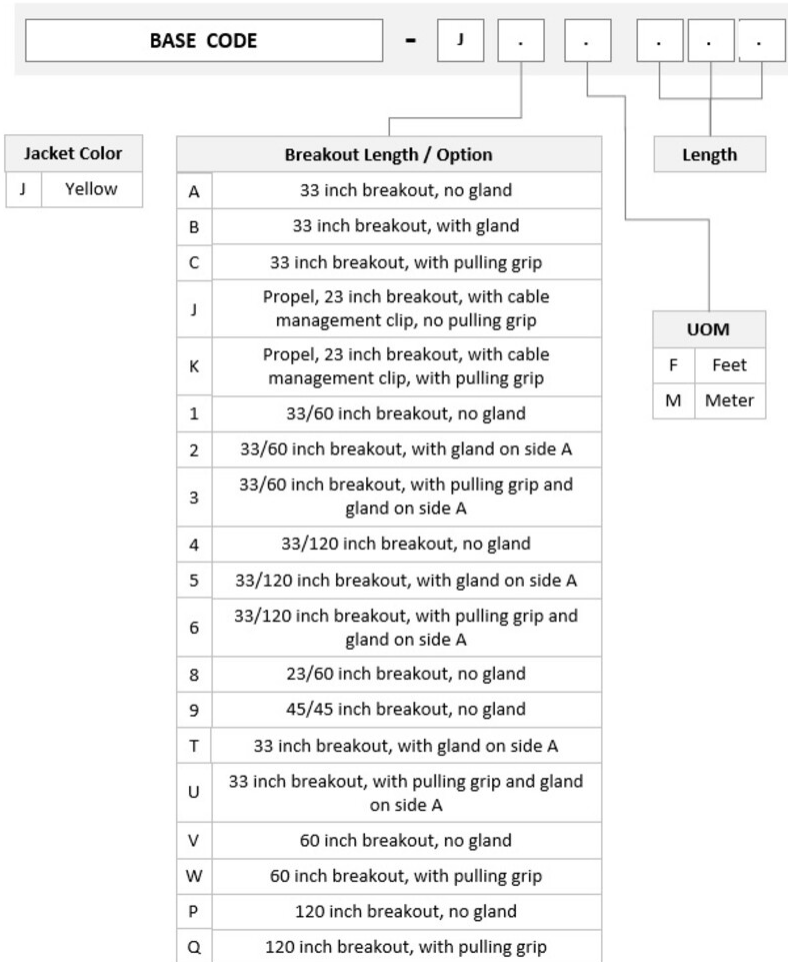

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0° | 4.40 lb @ 90°

## Optical Specifications

**Fiber Mode** Singlemode

**Fiber Type** G.657.A2, TeraSPEED®

## Environmental Specifications

# UJGMXMXCN

---

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Dual Rated LSZH/Riser

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

## Included Products

- 760249611  
N-192-MP-8G1-F12YL/20T/B2 - Fiber indoor cable, Low Smoke Zero Halogen Riser MPO Trunk, 192 fiber with 2.0 mm Subunits, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color, B2ca flame rating
- 860659010 - MPO-12, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 2mm