


FGS-MHXP-M/H

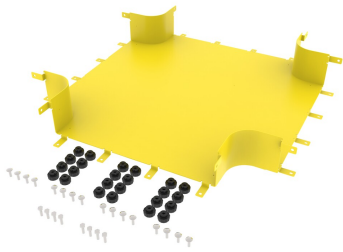

FiberGuide® Horizontal Cross with Dual 4x18in and Dual 4x24in Exits, Yellow

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Cross
Product Brand	FiberGuide®
Product Series	FGS

General Specifications

Color	Yellow
Orientation	Horizontal
Section Type	Cross section

Dimensions

Height	120 mm 4.724 in
Width	753 mm 29.646 in
Length	905 mm 35.63 in
System Dimensions	102 mm x 457 mm (4 in x 18 in) 102 mm x 610 mm (4 in x 24 in)

Ordering Tree

FGS-MHXP-M/H



Section Color

9	empty	yellow
	B	black

Section Size

10	A	4 x 4 in
	B	4 x 6 in
	B/F	4 x 12 in, with two 4 x 6 in exits
	B/F-VS	4 x 12 in, with two 4 x 6 in exits, variable support bracket
	C	2 x 2 in
	F	4 x 12 in
	F/H	4 x 24 in, with two 4 x 12 in exits
	F/H-VS	4 x 24 in, with two 4 x 12 in exits, variable support bracket
	F/VS	4 x 12 in, variable support bracket
	G	2 x 6 in
	H	4 x 24 in
	H-VS	4 x 24 in, variable support bracket
	M	4 x 18 in
	M/H	4 x 18 in, with two 4 x 24 in exits
M/F	4 x 18 in, with two 4 x 12 in exits	

* Support brackets only come in black

Material Specifications

Material Type Steel

Environmental Specifications

Safety Standard CSA | UL

Packaging and Weights

Weight, net 3.12 kg | 6.878 lb

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Below maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant

