

## IFEB50, Indoor Fiber Optic Wall mount Enclosure, Splice Only, Single Element Slim trays(44) Smouv, No cable Seals, RAL 9010

- Compact, wall mountable fiber enclosures for indoor use
- Specifically designed for fast FTTH deployment and easy customer connection
- Configurable as splice only or connectorized solution
- Multiple and modular wrap around cable port sealing options to suit a wide range of cables
- Easy intergration of 900µm connectorised or 250µm splice splitters
- Single Element (SE), Single Slim Element (SLE) or Single Circuit (SC) tray options - Smouv and ANT
- Powered by NOVUX™

### Product Classification

<b>Regional Availability</b>	EMEA
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber wall box
<b>Product Series</b>	IFEB-50

### General Specifications

<b>Functionality</b>	Splicing
<b>Access</b>	Front
<b>Adapter Ports, quantity</b>	0
<b>Cable Ports, quantity</b>	0
<b>Drop Port, quantity</b>	0
<b>Enclosure Color</b>	Pure White (RAL 9010)
<b>Front Cover Type</b>	Snap-on cover
<b>Interface</b>	Splicing only
<b>Pigtails Included, quantity</b>	0
<b>Splice Tray Construction</b>	SLE (Slim element tray for up to 12 primary coated fibers)
<b>Splicing Capacity, maximum</b>	528
<b>Splicing Type</b>	SMOUV

### Dimensions


<b>Height</b>	480 mm   18.898 in
<b>Height, with cover</b>	550 mm   21.654 in

# 760259801 | IFEB-50WAN000C44SNNNNN000

**Width** 360 mm | 14.173 in


**Depth** 175 mm | 6.89 in

## Dimension Drawing

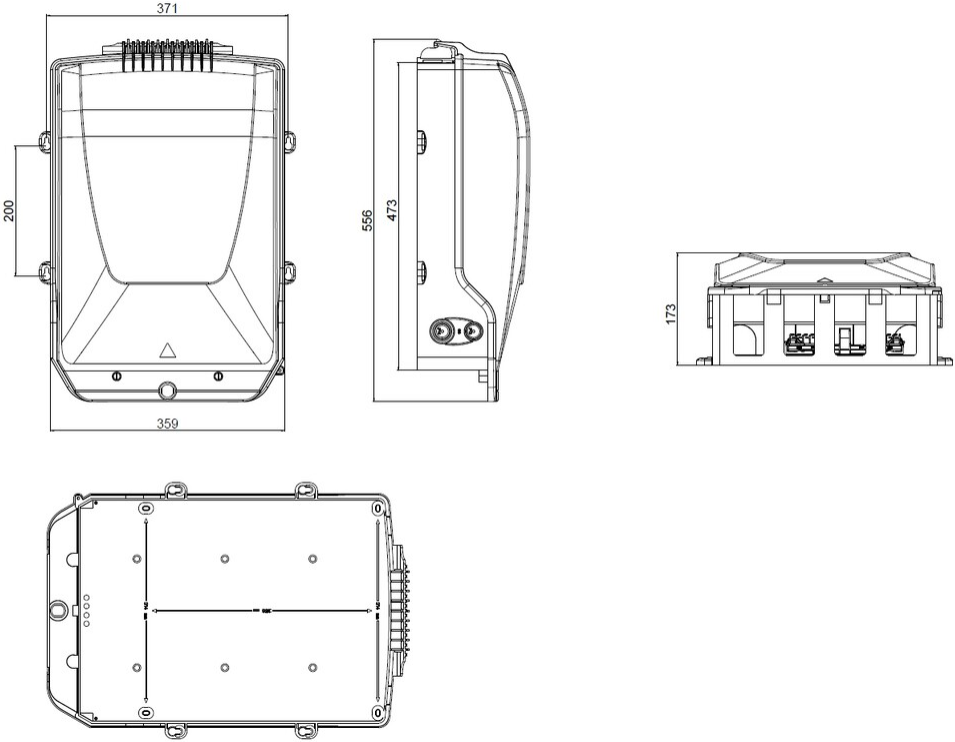

## Ordering Tree

# 760259801 | IFEB-50WAN000C44SNNNNN000

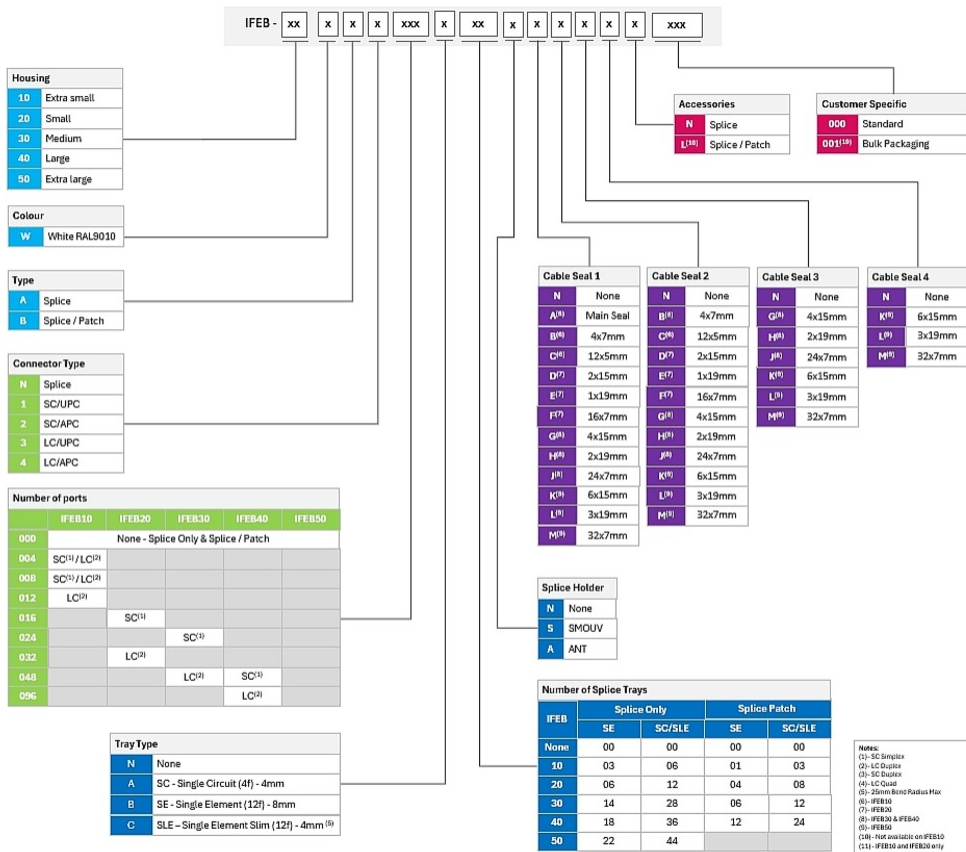

## Environmental Specifications

- Installation temperature** -5 °C to +45 °C (+23 °F to +113 °F)
- Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)
- Environmental Space** Indoor
- Flammability Rating** UL 94 V-0 | UL 94 V-0
- Qualification Standards** IEC 60529, IP50 | IEC 61753-1 Ed.2 2018 - Category C

## Packaging and Weights

- Included** Box (1) | Port blanking plates (4) | SLE Smouv trays (44)
- Packaging quantity** 1
- Packaging Type** Box

## Regulatory Compliance/Certifications

- Agency**
- Classification**

760259801 | IFEB-50WAN000C44SNNNNN000

---

CHINA-ROHS

Below maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on [www.commscope.com/ProductCompliance](http://www.commscope.com/ProductCompliance)

ROHS

Compliant

UK-ROHS

Compliant

