

SRC3-U1B1B3BE000



NOVUX™ Specialty Range Closure 100, splice/patch, 2x SC/UPC adapter, No pigtail, 1:4 splitter, 12 splices, SMOUV® 45mm splice protectors, black, NO splitter, 2x NVX-CR-TI-SM-NN cable retention

- Modern drop solution offering providers the agility and flexibility to use it in last-mile fiber network applications, both above and below ground
- Protected from harsh conditions by CommScope’s Octopus gel sealing technology
- Agnostic to connectivity technologies: splice, connector, field-installable connector for agility and flexibility
- Identification plate for either QR code or customer logo
- QR code and CommScope cTrak® app for one-click access to all product information

Product Classification

Regional Availability	Asia EMEA Latin America North America
Regional Availability Note	Contact your local CommScope representative for specific availability
Product Type	Access terminal, non-hardened
Product Brand	NOVUX™
Product Series	SRC100

General Specifications

Cable Capacity, Drop	4 Flat 8.0 x 4.5 mm (0.30 x 0.17 in) 4 Round 1.2–8.0 mm (0.05–0.31 in)
Cable Sealing Type	Compressed gel
Enclosure Color	Black
Lock Type	Hinged with latches
Mounting	Handhole Partially buried Pedestal Wall/Pole Mount, mounting kit included
Port Type	SC/UPC
Port, quantity	2
Splice Tray Included, quantity	1
Splice Tray Type Included	12-way, heat shrink
Splicing Capacity, maximum	12
Splicing Type, Supported	Single fusion
Splitter Type	1 x 4
Splitter, quantity	0

SRC3-U1B1B3BE000

Dimensions

Height	267 mm 10.512 in
Width	117 mm 4.606 in
Depth	49 mm 1.929 in

Ordering Tree

SRC

-U

000

Size and color

3

100 Black

4

100 Gray

Sealing

U

Underground, IP68

Connector type*

1

SC/UPC

2

LC/UPC

3

SC/APC

4

LC/APC

5

Splice only

*All connector types are grade B

Number of adapters

A

None

K

1

B

2

Cable retention

*

See complete details at the bottom of the page.

Splice protector type

A

ANT/SMOUV 30

B

SMOUV 45

F

Ribbon 12

Splitters

1

None

2

1:2

3

1:4

Number of splices

B

12

C

24

D

48

Number of pigtails

1

None

A

1

2

2

B

3

3

4

2 cable attachments are supplied.

Cable retention*

A

None

B

NVX-CR-MC-FT-NN

C

NVX-CR-MC-RD-NN

D

NVX-CR-SA-SM-NN

E

NVX-CR-TI-SM-NN

F

NVX-CR-DU-FL-NN

G

4xNVX-CR-MC-FT-NN

H

4xNVX-CR-MC-RD-NN

I

4xNVX-CR-SA-SM-NN

J

4xNVX-CR-TI-SM-NN

K


4xNVX-CR-DU-FL-NN

L

2xNVX-CR-MC-FT-NN and 2xNVX-CR-MC-RD-NN

Cable Termination Unit (CTU) options


B



NVX-CR-MC-FT-NN

- Flat cable
- Metal clip
- Range 3 x 5 to 4 x 8 mm


C



NVX-CR-MC-RD-NN

- Round cable
- Metal clip
- Range 4 to 6.2 mm


D



NVX-CR-SA-SM-NN

- Round cable
- Dia up to 8 mm
- Strength member
- Aramide yarns
- Single layer


E



NVX-CR-TI-SM-NN

- Round cable
- Dia up to 8 mm
- Aramide yarns
- Single layer

F



NVX-CR-DU-FL-NN

- Round cable
- Dia up to 6.2 mm
- Aramide yarns
- Dual layer
- Compact length

Material Specifications

Enclosure Material Type	Impact-resistant polymer
-------------------------	--------------------------

Optical Specifications

Fiber Type	G.657.A1 G.657.A2 G.657.B3
------------	--------------------------------

Page 2 of 4

©2025 CommScope, Inc. All rights reserved. CommScope and the CommScope logo are registered trademarks of CommScope and/or its affiliates in the U.S. and other countries. For additional trademark information see <https://www.commscope.com/trademarks>. All product names, trademarks and registered trademarks are property of their respective owners. Revised: June 27, 2025

COMMScope®

SRC3-U1B1B3BE000

Environmental Specifications

Operating Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Environmental Space	Above ground Below ground Direct burial
Qualification Standards	IEC 60529, IP68 + 2 m waterhead IEC 61753-1, category G
UV Resistance	UV stabilized


Packaging and Weights

Packaging quantity	1
Packaging Type	Box Carton

Included Products

NVX-CR-TI-SM-NN	–	NOVUX™ Cable Termination Unit (CTU) for round cables up to 8 mm diameter, with aramide yarns, single layer
-----------------	---	--

NVX-CR-TI-SM-NN

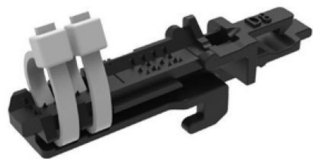

NOVUX™ Cable Termination Unit (CTU) for round cables up to 8 mm diameter, with aramide yarns, single layer

Product Classification

Regional Availability	Asia EMEA Latin America North America
Product Type	Cable termination kit
Product Brand	NOVUX™
Product Series	CSC

General Specifications

Application	For use with CSC Fiber closures
Color	Black

Packaging and Weights

Packaging quantity	20
Packaging Type	Bag Box

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

