

FMT-DST080A00-A16P

FMT Fiber Termination/Storage Panel, with sliding tray, 16 LC/UPC, singlemode, 1RU, 19 in, putty white



Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch/storage panel
Product Series	FMT

General Specifications


Functionality	Patching
Body Style	Symmetrical
Color	Black
Color, front	Putty white
Interface, front	LC/UPC
Rack Type	EIA 19 in EIA 23 in
Rack Units	1
Shelf Movement	Sliding
Total Ports, quantity	16

Dimensions

Height	44.45 mm 1.75 in
Width	482.6 mm 19 in
Depth	279.91 mm 11.02 in
Cable Stub Length	0 m 0 ft

Ordering Tree

FMT-DST080A00-A16P

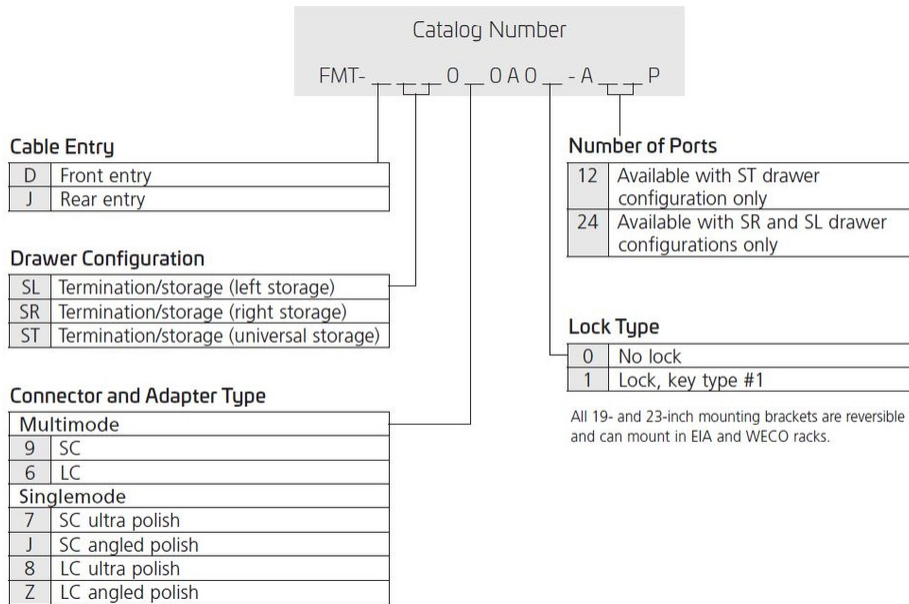

Material Specifications

Finish Powder coated

Material Type Steel

Optical Specifications

Fiber Mode Singlemode

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant

