

FMT-DTR023U20-S24B

FMT Fiber Termination/Splice Panel, with sliding tray, 24 FC/UPC, singlemode, 1RU, 19 in, black



OBSOLETE

This product was discontinued on: March 1, 2018

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch/splice panel
Product Series	FMT

General Specifications


Functionality	Patching Splicing
Body Style	Symmetrical
Color	Black
Color, front	Black
Interface, front	FC
Interface Feature, front	Standard
Rack Type	EIA 19 in EIA 23 in
Rack Units	1
Shelf Movement	Sliding
Total Ports, quantity	24

Dimensions

Height	44.45 mm 1.75 in
Width	482.6 mm 19 in
Depth	279.91 mm 11.02 in

FMT-DTR023U20-S24B

Ordering Tree

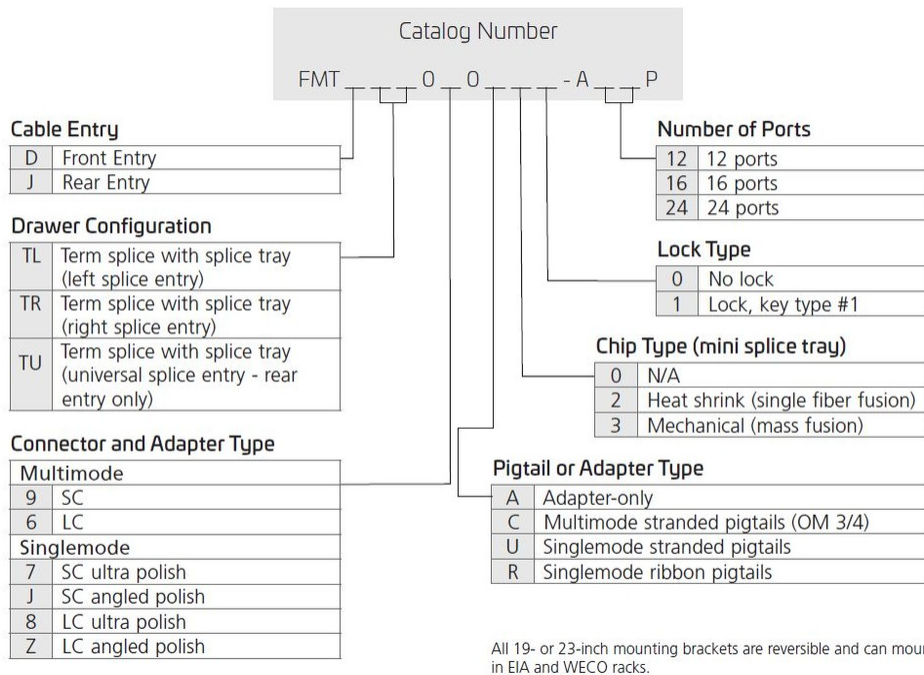

Material Specifications

Finish Powder coated

Material Type Steel

Optical Specifications

Fiber Mode Singlemode

Packaging and Weights

Included Mounting hardware

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted

FMT-DTR023U20-S24B

