

# FMT-JTU071U20-F24W

---



FMT Fiber Termination/Splice Panel, with sliding tray, 24 SC/UPC, singlemode, 1RU, 19 in, white

## Product Classification

<b>Regional Availability</b>	Latin America   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber patch/splice panel
<b>Product Series</b>	FMT

## General Specifications


<b>Functionality</b>	Patching   Splicing
<b>Body Style</b>	Symmetrical
<b>Color</b>	Black
<b>Color, front</b>	Putty white
<b>Interface, front</b>	SC
<b>Interface Feature, front</b>	Standard
<b>Rack Type</b>	EIA 19 in   EIA 23 in
<b>Rack Units</b>	1
<b>Shelf Movement</b>	Sliding
<b>Total Ports, quantity</b>	24

## Dimensions

<b>Height</b>	44.45 mm   1.75 in
<b>Width</b>	482.6 mm   19 in
<b>Depth</b>	279.91 mm   11.02 in

## Ordering Tree

# FMT-JTU071U20-F24W

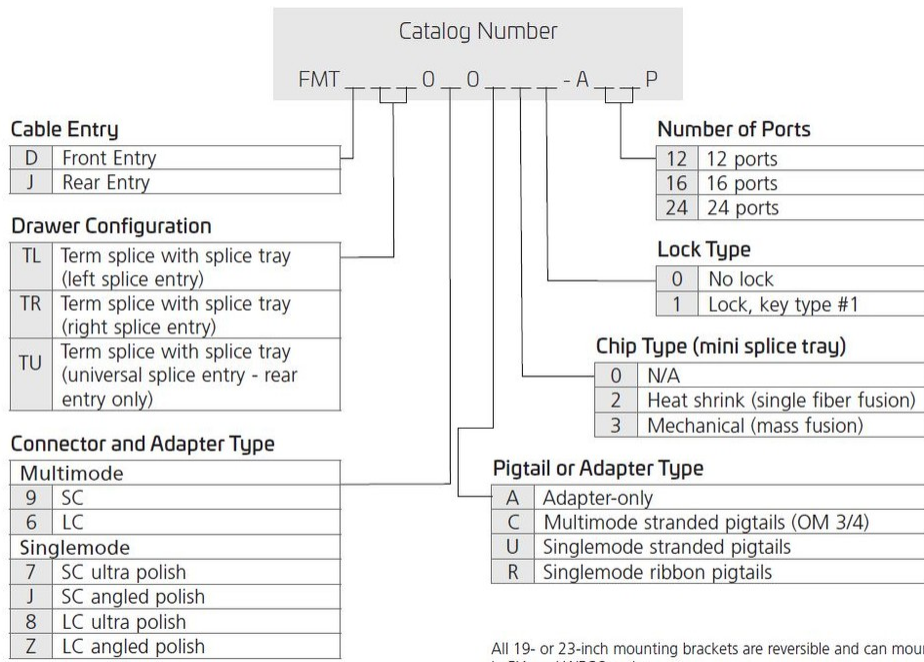

All 19- or 23-inch mounting brackets are reversible and can mount in EIA and WECCO racks.

## Material Specifications

<b>Finish</b>	Powder coated
<b>Material Type</b>	Steel

## Optical Specifications

<b>Fiber Mode</b>	Singlemode
-------------------	------------

## Packaging and Weights

<b>Included</b>	Mounting hardware
<b>Packaging quantity</b>	1

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted

