


ODB-24DLC-24PC-HC3

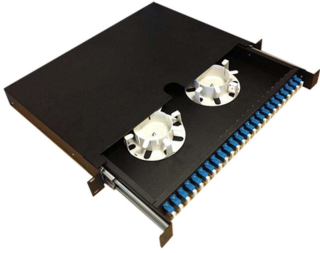

HELIAX® 24-port (48 fiber) patch panel for 19in cabinet, includes sliding Panel, 24 prepopulated singlemode adapters, 24 DLC-DLC single mode patch cords, 2 fiber tie

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch panel
Product Brand	HELIAX®

General Specifications

Application	Protects unused fiber fan-outs near the radio equipment
Color	Black
Interface, front	LC/UPC
Pigtails Included, quantity	24
Rack Type	EIA 19 in
Rack Units	1
Shelf Movement	Sliding
Total Ports, quantity	24

Dimensions

Height	43.2 mm 1.701 in
Width	429 mm 16.89 in
Depth	307 mm 12.087 in

Packaging and Weights

Weight, net	5.443 kg 12 lb
--------------------	------------------

Regulatory Compliance/Certifications

ODB-24DLC-24PC-HC3

Agency**Classification**

CHINA-ROHS

Below maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant

