


FD3-AC144J00JABP1

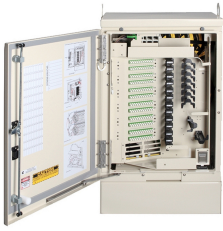

FDH 3000 Fiber Distribution Extra Small Cabinet, 144F, SC/APC, no splitters, die. loose tube, 100 ft, 12F

Product Classification

Regional Availability	North America
Product Type	Fiber distribution hub
Product Series	FDH 3000

General Specifications

Access	Front
Cable Type	Dielectric - Loose Tube
Color	Putty white
Distribution Cables, quantity	2
Distribution Ports, quantity	144
Fibers per Distribution Cable, quantity	72
Fibers per Feeder Cable, quantity	12
Interface, Input	SC
Interface Feature, Input	APC
Mounting	Pad
Splitter Slots, quantity	9

Dimensions

Height	914 mm 35.984 in
Width	533 mm 20.984 in
Depth	356 mm 14.016 in
Cable Length	30.48 m 100 ft
Enclosure Size	Extra small

Material Specifications

Finish	Powder coated
Material Type	Steel

FD3-AC144J00JABP1

Environmental Specifications

Environmental Space Above ground

Packaging and Weights

Packaging quantity 1

Packaging Type Pallet