


BR4383-000 | FIST-GPS2-K-NNN-0-CO

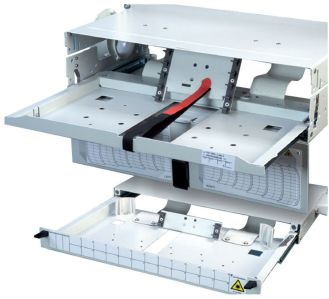

FIST-GPS2 Fiber Panel for holding up to 2 GPST Patch/Splice Trays, unloaded, 1RU, 19 in, gray

Product Classification

Regional Availability	EMEA
Portfolio	CommScope®
Product Type	Fiber patch/splice panel
Product Brand	FIST®
Product Series	FIST-GPS2

General Specifications

Functionality	Patching Splicing
Application	Used in FIST-GR3-style frames only
Color	Gray
Color, front	Gray
Growth Configuration	Unloaded
Rack Type	EIA 19 in ETSI 600 mm
Rack Units	1
Shelf Movement	Sliding

Dimensions

Height	44.45 mm 1.75 in
Width	482.6 mm 19 in

Material Specifications

Finish	Powder coated
Material Type	Galvanized steel

BR4383-000 | FIST-GPS2-K-NNN-0-CO

Environmental Specifications

Operating Temperature -5 °C to +45 °C (+23 °F to +113 °F)

Storage Temperature -30 °C to +60 °C (-22 °F to +140 °F)

Relative Humidity Up to 93%, non-condensing

Packaging and Weights

Included Mounting hardware

Packaging quantity 1

Regulatory Compliance/Certifications

Agency

CHINA-ROHS

REACH-SVHC

ROHS

Classification

Below maximum concentration value

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

Compliant

