


EH3096-000 | OCM6-SP11WSSL1-61C11

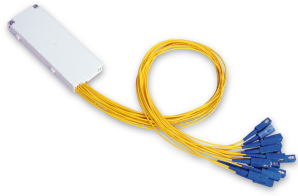

OCM6 Fiber Optic Splitter Module, Planar, one 1x32 Splitter, singlemode, LC/UPC, symmetrical split ratio, in-line style, 61 cm pigtails

Product Classification

Regional Availability	EMEA
Portfolio	CommScope®
Product Type	Splitter module
Product Series	OCM6

General Specifications

Device Type	Standard VAM
Functionality	Splitting
Technology Type	Planar lightwave circuit (PLC)
Application	For use with BUDI wall boxes
Circuits, quantity	1
Distribution Type	1 x 32 splitter
Interface, Input	LC/UPC
Interface, Output	LC/UPC
Split Ratio	Symmetrical
Splitter, quantity	1

Dimensions

Height	130 mm 5.118 in
Width	49.8 mm 1.961 in
Depth	16.5 mm 0.65 in
Pigtail Length, Output	0.61 m 2.001 ft
Pigtail Diameter	1.8 mm 0.071 in

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency**Classification**

CHINA-ROHS

Below maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant

