


# FPS-MPPRACKMT24

---

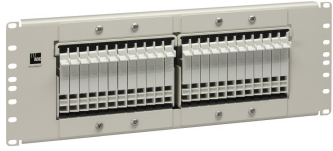

FDH 3000 Splitter panel for holding up to 24 Plug-and-play splitter modules, 4U putty white

## Product Classification

<b>Regional Availability</b>	North America
<b>Product Type</b>	Chassis
<b>Product Series</b>	FDH 3000

## General Specifications

<b>Application</b>	For use in FDH 3000 cabinets
<b>Color</b>	Putty white

## Dimensions

<b>Height</b>	177.8 mm   7 in
<b>Width</b>	482.6 mm   19 in

## Environmental Specifications

<b>Flammability Rating</b>	UL 94 V-0
----------------------------	-----------

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

