


# C74992-000 | FIST-GSS2-KIT16

---

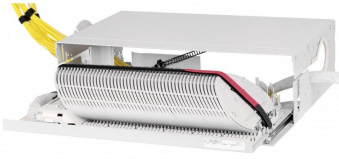

FIST-GSS2 Fiber Splice Panel, 3RU, Etsi, for splicing central core cable to pigtail, trays included, gray

## Product Classification

|                              |                    |
|------------------------------|--------------------|
| <b>Regional Availability</b> | EMEA               |
| <b>Portfolio</b>             | CommScope®         |
| <b>Product Type</b>          | Fiber splice panel |
| <b>Product Brand</b>         | FIST®              |
| <b>Product Series</b>        | FIST-GSS2          |

## General Specifications

|  |                                       |
|--|---------------------------------------|
| <b>Functionality</b>                   | Splicing                              |
| <b>Application</b>                     | Compatible with FIST-GR3-style frames |
| <b>Cable Exit Location</b>             | Rear, right side                      |
| <b>Color</b>                           | Gray                                  |
| <b>Interface, front</b>                | Unloaded                              |
| <b>Patch Cord Routing</b>              | Left sided                            |
| <b>Rack Type</b>                       | ETSI 600 mm   FIST-GR3                |
| <b>Rack Units</b>                      | 3                                     |
| <b>Shelf Movement</b>                  | Sliding                               |
| <b>Splice Trays Included, quantity</b> | 48                                    |
| <b>Splicing Capacity, maximum</b>      | 96                                    |
| <b>Splicing Type</b>                   | Heat shrink, single fiber fusion      |

## Dimensions

|               |                     |
|---------------|---------------------|
| <b>Height</b> | 133.35 mm   5.25 in |
| <b>Width</b>  | 482.6 mm   19 in    |

## Material Specifications

|                      |                  |
|----------------------|------------------|
| <b>Finish</b>        | Powder coated    |
| <b>Material Type</b> | Galvanized steel |

## Environmental Specifications

|                              |                                      |
|------------------------------|--------------------------------------|
| <b>Operating Temperature</b> | -5 °C to +45 °C (+23 °F to +113 °F)  |
| <b>Storage Temperature</b>   | -30 °C to +60 °C (-22 °F to +140 °F) |
| <b>Relative Humidity</b>     | Up to 93%, non-condensing            |

## Packaging and Weights

|                           |                   |
|---------------------------|-------------------|
| <b>Included</b>           | Mounting hardware |
| <b>Packaging quantity</b> | 1                 |

## Regulatory Compliance/Certifications

| <b>Agency</b> | <b>Classification</b>  |
|---------------|--|
| CHINA-ROHS    | Below maximum concentration value  |
| REACH-SVHC    | Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS          | Compliant  |
| UK-ROHS       | Compliant  |

