

FL2-CF80192AN-8C50

FL2000 Fiber Termination/Splice Panel, no pigtailed, 192 LC/UPC, singlemode, 10RU, 19 in, putty white

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch/splice panel
Product Series	FL2000

General Specifications


Functionality	Patching Splicing
Adapter Packs Included, quantity	16
Cable Exit Location	Rear, left side Rear, right side
Color	Putty white
Color, front	Putty white
Growth Configuration	Fully loaded
Interface, front	LC/UPC
Patching Capacity, maximum	192
Rack Type	EIA 19 in
Rack Units	10
Shelf Movement	Hinged
Splicing Capacity, maximum	192
Total Ports, quantity	192

Dimensions

Height	444.5 mm 17.5 in
Width	482.6 mm 19 in
Depth	256.54 mm 10.1 in

Ordering Tree

FL2-CF80192AN-8C50

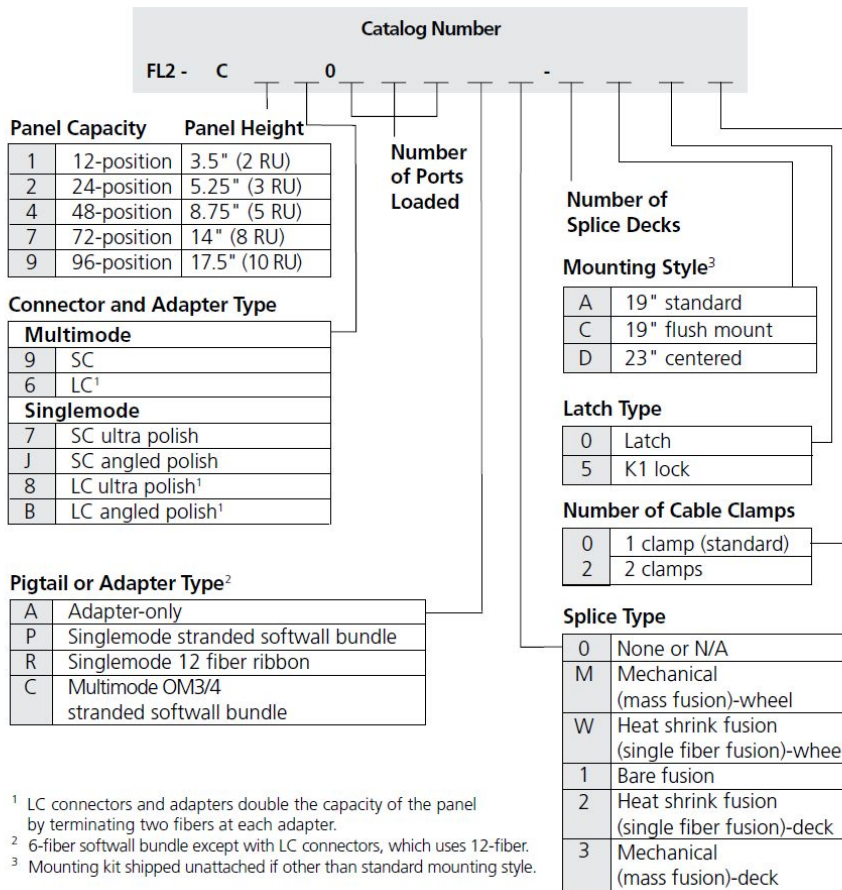

Material Specifications

Finish	Powder coated
Material Type	Steel

Optical Specifications

Fiber Mode	Singlemode
-------------------	------------

Environmental Specifications

Operating Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Storage Temperature	-40 °C to +85 °C (-40 °F to +185 °F)

Packaging and Weights

Included	Mounting hardware
Packaging quantity	1

FL2-CF80192AN-8C50

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Above maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant/Exempted

UK-ROHS

Compliant/Exempted

