

FL2-R490048A0-0A00



FL2000 Fiber Termination Panel, 48 SC/UPC, multimode, 3RU, 19 in, putty white

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch panel
Product Series	FL2000

General Specifications


Functionality	Patching
Adapter Packs Included, quantity	8
Color	Putty white
Color, front	Putty white
Growth Configuration	Fully loaded
Interface, front	SC/UPC
Patching Capacity, maximum	48
Rack Type	EIA 19 in
Rack Units	3
Shelf Movement	Hinged
Splicing Capacity, maximum	0
Total Ports, quantity	48

Dimensions

Height	133.35 mm 5.25 in
Width	482.6 mm 19 in
Depth	256.54 mm 10.1 in

Ordering Tree

FL2-R490048A0-0A00

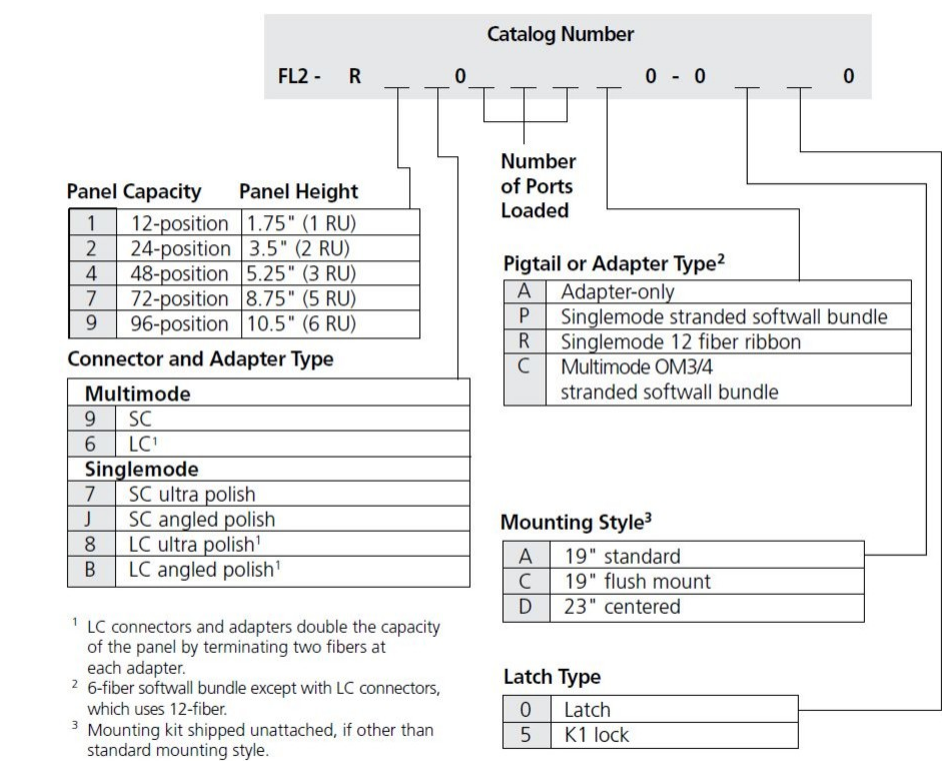

Material Specifications

Finish	Powder coated
Material Type	Steel

Optical Specifications

Fiber Mode	Multimode
------------	-----------

Environmental Specifications

Operating Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Storage Temperature	-40 °C to +85 °C (-40 °F to +185 °F)

Packaging and Weights

Included	Mounting hardware
Packaging quantity	1

Regulatory Compliance/Certifications

FL2-R490048A0-0A00

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

