


FL2-R970096A0-0A00

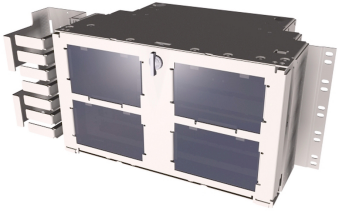

FL2000 Fiber Termination Panel, 96 SC/UPC, singlemode, 6RU, 19 in, putty white

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch panel
Product Series	FL2000

General Specifications


Functionality	Patching
Adapter Packs Included, quantity	16
Color	Putty white
Color, front	Putty white
Growth Configuration	Fully loaded
Interface, front	SC/UPC
Patching Capacity, maximum	96
Rack Type	EIA 19 in
Rack Units	6
Shelf Movement	Hinged
Splicing Capacity, maximum	0
Total Ports, quantity	96

Dimensions

Height	266.7 mm 10.5 in
Width	482.6 mm 19 in
Depth	266.7 mm 10.5 in

Ordering Tree

FL2-R970096A0-0A00

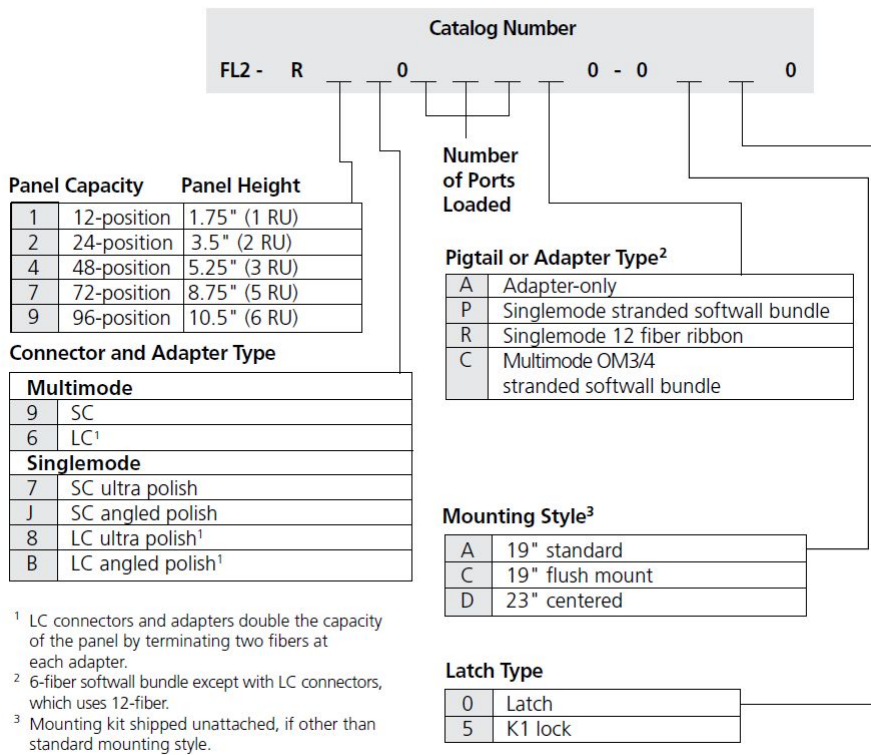

Material Specifications

Finish	Powder coated
Material Type	Steel

Optical Specifications

Fiber Mode	Singlemode
-------------------	------------

Environmental Specifications

Operating Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Storage Temperature	-40 °C to +85 °C (-40 °F to +185 °F)

Packaging and Weights

Included	Mounting hardware
Packaging quantity	1

Regulatory Compliance/Certifications

FL2-R970096A0-0A00

Agency**Classification**

CHINA-ROHS

Above maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant/Exempted

UK-ROHS

Compliant/Exempted

