


FL2-R980144A0-0A00

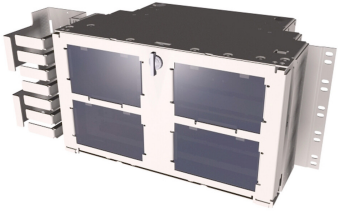

FL2000 Fiber Termination Panel, 144 LC/UPC, singlemode, 6RU, 19 in, putty white

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch panel
Product Series	FL2000

General Specifications


Functionality	Patching
Adapter Packs Included, quantity	12
Color	Putty white
Growth Configuration	Partially loaded
Interface, front	LC/UPC
Rack Type	EIA 19 in
Rack Units	6
Shelf Movement	Hinged
Splicing Capacity, maximum	0
Total Ports, quantity	144

Dimensions

Height	266.7 mm 10.5 in
Width	482.6 mm 19 in
Depth	256.54 mm 10.1 in

Ordering Tree

FL2-R980144A0-0A00

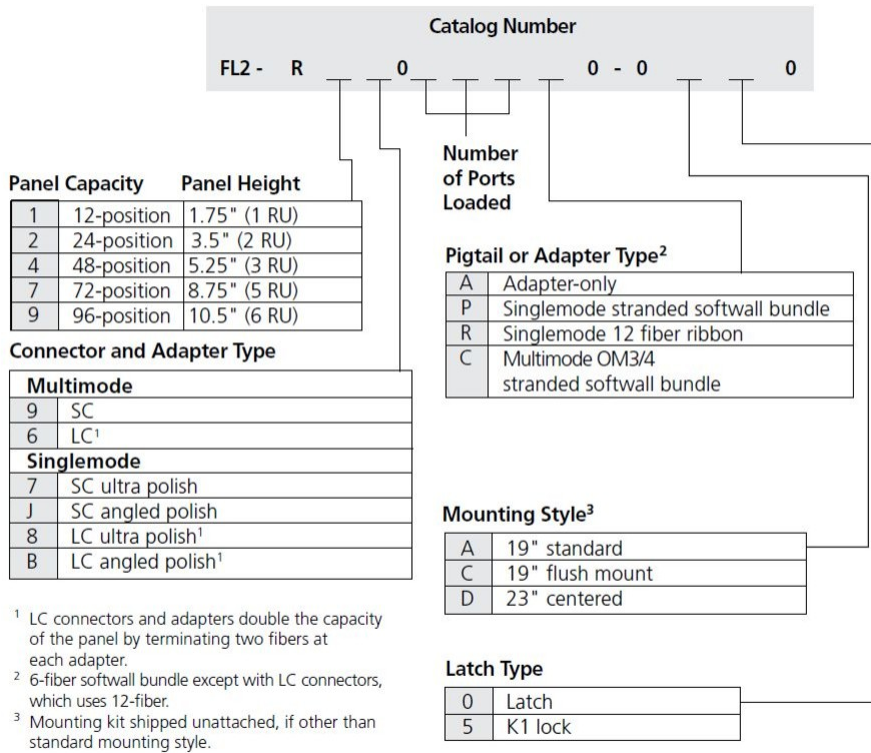

Material Specifications

Finish Powder coated

Material Type Steel

Optical Specifications

Fiber Mode Singlemode

Environmental Specifications

Operating Temperature -40 °C to +70 °C (-40 °F to +158 °F)

Storage Temperature -40 °C to +85 °C (-40 °F to +185 °F)

Packaging and Weights

Included Mounting hardware

Packaging quantity 1

Regulatory Compliance/Certifications

FL2-R980144A0-0A00

Agency

CHINA-ROHS

ISO 9001:2015

REACH-SVHC

ROHS

UK-ROHS

Classification

Below maximum concentration value

Designed, manufactured and/or distributed under this quality management system

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

Compliant

Compliant/Exempted

