

FL2-S7B0AH046-DU00

FL2000 Fiber Termination Panel, 144 LC/APC, singlemode, 5RU, 23 in, putty white, pre-terminated with IFC cable, 46 meters, Stub tail at far end

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch panel, with IFC cable
Product Series	FL2000

General Specifications


Functionality	Patching
Adapter Packs Included, quantity	12
Cable Exit Location	Upward
Cable Stub Type	IFC
Color	Putty white
Growth Configuration	Fully loaded
Interface, front	LC/APC
Interface, rear	Stub tail
Rack Type	EIA 23 in
Rack Units	5
Shelf Movement	Hinged
Splicing Capacity, maximum	0
Total Ports, quantity	144

Dimensions

Height	222.25 mm 8.75 in
Width	584.2 mm 23 in
Depth	256.54 mm 10.1 in
Cable Length	46 m 150.919 ft

Ordering Tree

FL2-S7B0AH046-DU00

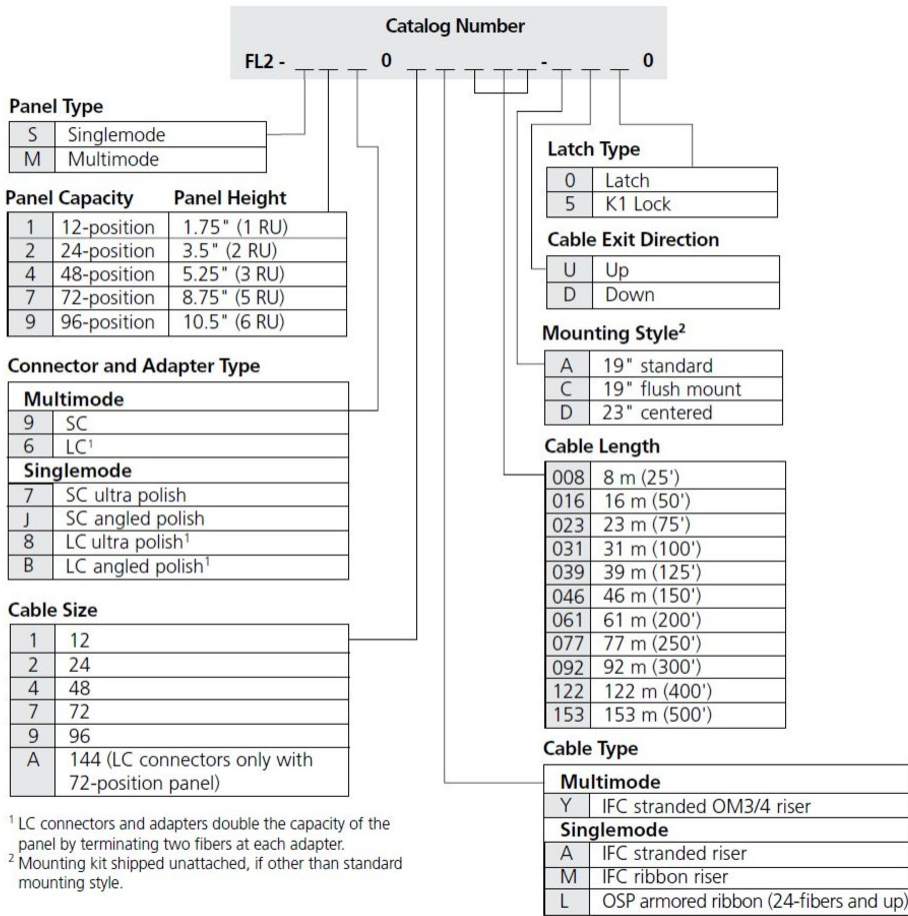

Material Specifications

Finish Powder coated

Material Type Steel

Optical Specifications

Fiber Mode Singlemode

Environmental Specifications

Operating Temperature -40 °C to +70 °C (-40 °F to +158 °F)

Storage Temperature -40 °C to +85 °C (-40 °F to +185 °F)

Packaging and Weights

Packaging quantity 1

FL2-S7B0AH046-DU00

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

