

TFP-24APRQ2DE3



TFP Fiber Optic Adapter Pack, 24-fiber, 2 pigtail assemblies, Multimode, LC, quad, right, aqua

Product Classification

| | |
|------------------------------|--------------------------------------|
| Regional Availability | Asia Latin America North America |
| Portfolio | NETCONNECT® |
| Product Type | Fiber adapter pack with pigtails |
| Product Series | TFP |

General Specifications


| | |
|-------------------------------------|--------------------------------------|
| Application | For use with TFP panels |
| Adapter Color | Aqua |
| Adapters, quantity, front | 6 |
| Body Style | Quad Right orientation |
| Color, front | Black |
| Interface | LC/UPC |
| Pigtail Assembly Type | Color-coded, 900 µm Pigtail bundle |
| Pigtails Included, quantity | 24 |
| Total Fibers, quantity | 24 |
| Total Ports, quantity, front | 24 |

Dimensions

| | |
|-----------------------|---------------------|
| Height | 33.53 mm 1.32 in |
| Width | 176.02 mm 6.93 in |
| Pigtail Length | 3 m 9.843 ft |

Ordering Tree

TFP-24APRQ2DE3

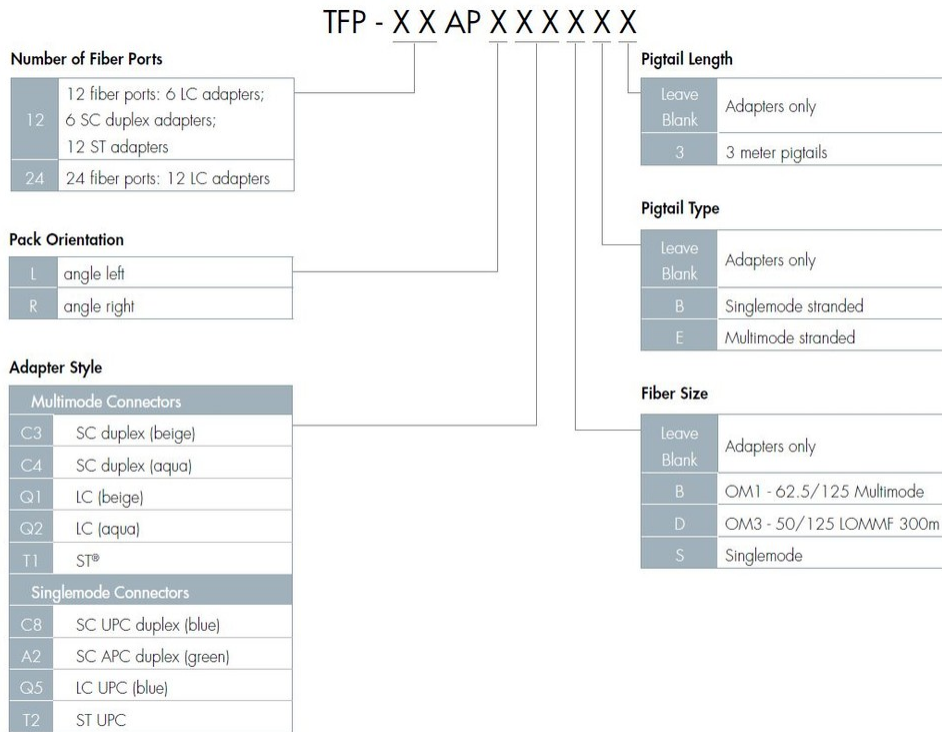

Optical Specifications

| | |
|--------------------------------|-----------|
| Fiber Mode | Multimode |
| Fiber Type | OM3 |
| Insertion Loss, maximum | 0.3 dB |
| Return Loss, minimum | 20 dB |

Environmental Specifications

| | |
|------------------------------|--------------------------------------|
| Operating Temperature | 0 °C to +70 °C (+32 °F to +158 °F) |
| Storage Temperature | -40 °C to +70 °C (-40 °F to +158 °F) |

Packaging and Weights

| | |
|---------------------------|--------------|
| Packaging quantity | 1 |
| Packaging Type | Bag Carton |

Regulatory Compliance/Certifications

| Agency | Classification |
|------------|-----------------------------------|
| CHINA-ROHS | Below maximum concentration value |

TFP-24APRQ2DE3

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant/Exempted

