

F3ZMPMXAL

Base Product



OM3 MPO (Unpinned) to MPO (Pinned), InstaPATCH® 360 Pre-terminated Trunk Cable, 96-Fiber, Low Smoke Zero Halogen B2ca

Product Classification

| | |
|------------------------------|---|
| Regional Availability | Europe |
| Portfolio | CommScope® |
| Product Type | Fiber trunk cable assembly |
| Product Brand | SYSTIMAX InstaPATCH® 360 |
| Ordering Note | For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration Not available in the United States or Canada |

General Specifications

| | |
|-------------------------------------|-------------------|
| Color, boot A | Black |
| Color, connector A | Aqua |
| Color, boot B | Black |
| Color, connector B | Aqua |
| Construction Type | Stranded |
| Furcation Color | Aqua |
| Interface, Connector A | MPO-12/UPC Female |
| Interface, Connector B | MPO-12/UPC Male |
| Jacket Color | Aqua |
| Polarity | Method B (LL) |
| Fibers per Subunit, quantity | 12 |
| Total Fibers, quantity | 96 |

Dimensions


| | |
|------------------------|-------|
| Breakout Length | 33 in |
|------------------------|-------|

F3ZMPMXAL

Cable Assembly Length Range (m) 3 – 999

Cable Assembly Length Range (ft) 10 – 999

Ordering Tree

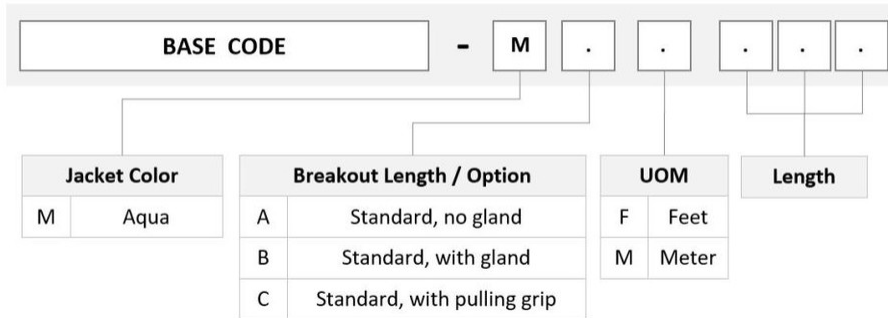

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Multimode

Fiber Type OM3, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

EN50575 CPR Cable EuroClass Fire Performance B2ca

Environmental Space Indoor | Low Smoke Zero Halogen (LSZH)

Regulatory Compliance/Certifications

| Agency | Classification |
|---------------|--|
| ANATEL | Compliant |
| CHINA-ROHS | Above maximum concentration value |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |
| REACH-SVHC | Compliant as per SVHC revision on www.commscope.com/ProductCompliance |
| ROHS | Compliant/Exempted |
| UK-ROHS | Compliant/Exempted |

F3ZMPMXAL



Included Products

- 760239597
N-096-MP-5L-F12AQ/B2 - Fiber indoor cable, LazrSPEED®, Low Smoke Zero Halogen Riser MPO Trunk, 96 fiber, 12 fiber subunits, Multimode OM3, Gel-free, Feet jacket marking, Aqua jacket color, B2ca flame rating
- 860647047 - MPO12, LOW LOSS, MALE, OM3/4, AQUA, 3mm
- 860647054 - MPO12, LOW LOSS, FEMALE, OM3/4, AQUA, 3mm