


FFXSCSC42

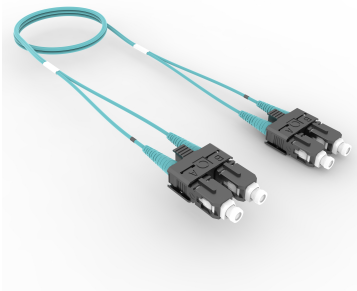

OM4 SC/UPC to SC/UPC, Fiber Patch Cord, 1.6 mm Duplex, Low Smoke Zero Halogen (LSZH)

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber patch cord, duplex
Product Brand	SYSTIMAX InstaPATCH® 360
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications


Color, boot A	Aqua
Color, connector A	Black
Color, boot B	Aqua
Color, connector B	Black
Interface, Connector A	SC/UPC
Interface, Connector B	SC/UPC
Jacket Color	Aqua
Polarity	Pairs, flipped
Total Fibers, quantity	2

Dimensions

Cable Assembly Length Range (m)	1 – 999
Cable Assembly Length Range (ft)	1 – 999
Diameter Over Jacket	1.6 mm 0.063 in

Ordering Tree

FFXSCSC42

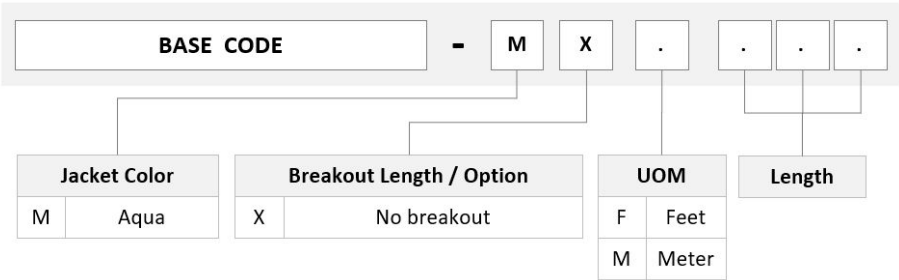

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Multimode
Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)
Operating Temperature, pending approval -20 °C to +70 °C (-4 °F to +158 °F)
Environmental Space Dual Rated LSZH/Riser

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant



FFXSCSC42

Included Products

- | | | |
|---------------------|---|--|
| 760021659 | – | Fiber Indoor Cable, LazrSPEED® 1.6 mm Low Smoke Zero Halogen Riser, 2-fiber Zipcord, |
| N-002-ZC-5K-F16AQ/E | | Multimode OM4, Feet jacket marking, Aqua jacket color, Eca Flame Rating |
| 860652876 | – | SC/PC Connector, Multimode, Aqua |