


# FGZMPMPAF

## Base Product

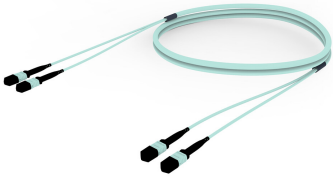

OM3 MPO (Unpinned) to MPO (Unpinned), InstaPATCH® 360 Pre-terminated Trunk Cable, 24-Fiber, Plenum

## Product Classification

|                              |  |
|------------------------------|--|
| <b>Regional Availability</b> | Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America               |
| <b>Portfolio</b>             | CommScope®   |
| <b>Product Type</b>          | Fiber trunk cable assembly   |
| <b>Product Brand</b>         | SYSTIMAX InstaPATCH® 360   |
| <b>Ordering Note</b>         | For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration |

## General Specifications


|                                     |                   |
|-------------------------------------|-------------------|
| <b>Color, boot A</b>                | Black             |
| <b>Color, connector A</b>           | Aqua              |
| <b>Color, boot B</b>                | Black             |
| <b>Color, connector B</b>           | Aqua              |
| <b>Construction Type</b>            | Stranded          |
| <b>Furcation Color</b>              | Aqua              |
| <b>Interface, Connector A</b>       | MPO-12/UPC Female |
| <b>Interface, Connector B</b>       | MPO-12/UPC Female |
| <b>Jacket Color</b>                 | Aqua              |
| <b>Polarity</b>                     | Method B (LL)     |
| <b>Fibers per Subunit, quantity</b> | 12                |
| <b>Total Fibers, quantity</b>       | 24                |

## Dimensions

|   |          |
|---|----------|
| <b>Breakout Length</b>                  | 33 in    |
| <b>Cable Assembly Length Range (m)</b>  | 3 – 999  |
| <b>Cable Assembly Length Range (ft)</b> | 10 – 999 |

# FGZMPMPAF

## Ordering Tree

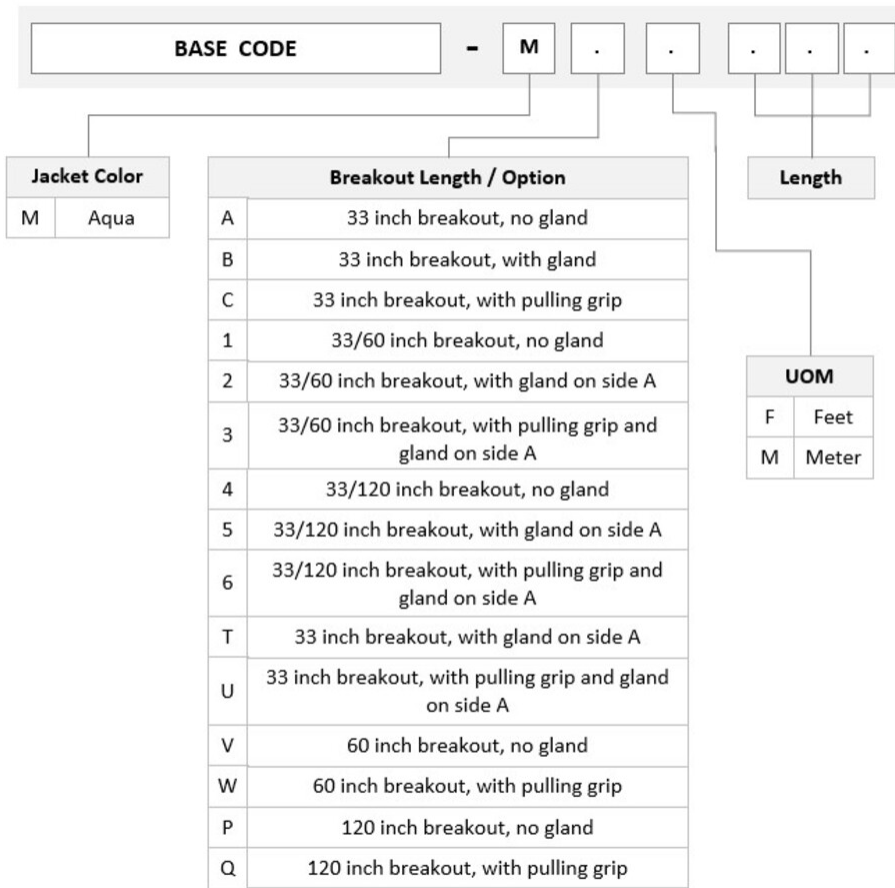

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0° | 4.40 lb @ 90°

## Optical Specifications

**Fiber Mode** Multimode

**Fiber Type** OM3, LazrSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Indoor | Plenum

# FGZMPMPAF

---

## Regulatory Compliance/Certifications

| Agency        | Classification   |
|---------------|--|
| ANATEL        | Compliant  |
| CHINA-ROHS    | Below maximum concentration value  |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system   |
| REACH-SVHC    | Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS          | Compliant  |
| UK-ROHS       | Compliant  |



## Included Products

- 760131151  
P-024-MP-5L-F12RD – Fiber indoor cable, LazrSPEED® Plenum MPO Trunk, 24 fiber with 12 fiber subunits, Multimode OM3, Feet jacket marking, Red jacket color
- 860647054 – MPO12, LOW LOSS, FEMALE, OM3/4, AQUA, 3mm