

FKZMPMXAM

Base Product



OM3 MPO (Unpinned) to MPO (Pinned), InstaPATCH® 360 Armored Pre-terminated Trunk Cable, 144-Fiber, Low Smoke Zero Halogen

OBSOLETE

This product was discontinued on: October 7, 2024

Replaced By:

UKXMPMXCM

Ultra Low Loss (ULL) Multimode OM4 MPO12 (Unpinned) to MPO12 (Pinned), Armored Pre-terminated Trunk Cable, 144-Fiber, Low Smoke Zero Halogen (LSZH)

Product Classification

Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

Portfolio

CommScope®

Product Type

Fiber trunk cable assembly

Product Brand

SYSTIMAX InstaPATCH® 360

Ordering Note

For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration | Not available in the United States or Canada

General Specifications

Color, boot A	Black
Color, connector A	Aqua
Color, boot B	Black
Color, connector B	Aqua
Construction Type	Armored Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-12/UPC Female
Interface, Connector B	MPO-12/UPC Male
Jacket Color	Aqua
Polarity	Method B (LL)
Fibers per Subunit, quantity	12

FKZMPMXAM

Total Fibers, quantity 144


Dimensions

Breakout Length 33 in

Cable Assembly Length Range (m) 3 – 999

Cable Assembly Length Range (ft) 10 – 999

Ordering Tree

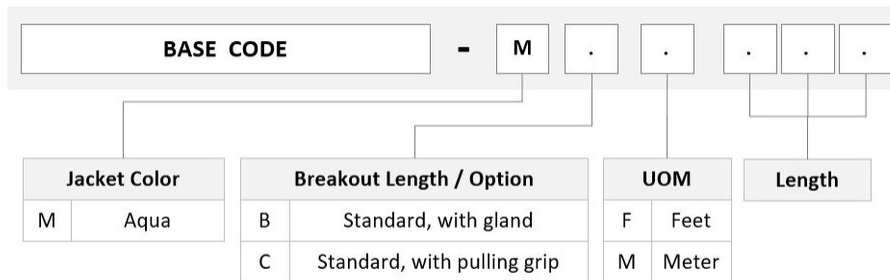

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Multimode

Fiber Type OM3, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Dual Rated LSZH/Riser | Indoor

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted

FKZMPMXAM

UK-ROHS

Compliant/Exempted



Included Products

- 860647047 – MPO12, LOW LOSS, MALE, OM3/4, AQUA, 3mm
- 860647054 – MPO12, LOW LOSS, FEMALE, OM3/4, AQUA, 3mm
- N-144-MZ-5L-F12 – Fiber indoor cable, LazrSPEED® Riser/LSZH rated, MPO Trunk, interlocking aluminum armored, Multimode OM3, 144 fiber multi-unit with 12 fiber subunits, Feet jacket marking, B2ca flame rating