


# FLZLCUCAF

## Base Product

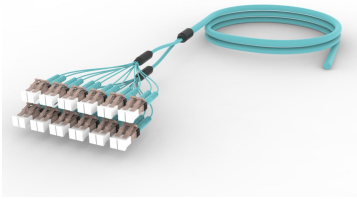

OM3 LC/UPC to Unconnectorized 24-Fiber InstaPATCH® 360 Ruggedized Fanout Cable, Plenum

## Product Classification

### Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

### Portfolio

CommScope®

### Product Type

Ruggedized fanout

### Product Brand

SYSTIMAX InstaPATCH® 360

### Ordering Note

For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

## General Specifications

### Color, boot A

Aqua

### Color, connector A

Beige

### Construction Type

Stranded

### Furcation Color

Aqua

### Interface, Connector A

LC/UPC

### Interface, Connector B

Unterminated

### Jacket Color

Aqua

### Fibers per Subunit, quantity

12

### Total Fibers, quantity

24

## Dimensions

### Cable Assembly Length Range (m)

3 – 305

### Cable Assembly Length Range (ft)

8 – 999

## Ordering Tree

# FLZLCUCAF



## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

**Fiber Mode** Multimode

**Fiber Type** OM3, LazrSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Indoor | Plenum

## Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant

# FLZLCUCAF

---



## Included Products

- 760038463  
P-024-MP-5L-F12AQ
  - 860637378
- Fiber indoor cable, LazrSPEED® Plenum MPO Trunk, 24 fiber with 12 fiber subunits, Multimode OM3, Feet jacket marking, Aqua jacket color
  - LazrSPEED® Elite LC Connector duplex for 1.6 mm Fiber, multimode