


# U3VMXMxAk

## Base Product

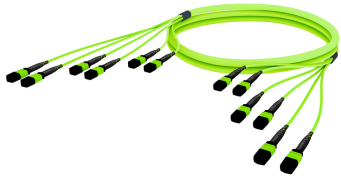

Ultra Low Loss (ULL) OM5 MPO12 (Pinned) to MPO12 (Pinned), Fiber Trunk Cable Assembly, 72-Fiber, Low Smoke Zero Halogen (LSZH)

This product will be discontinued on: April 30, 2024

### Replaced By:

U3VMXMxCK

Ultra Low Loss ULL LazrSPEED® 550 OM5 MPO(Pinned) to MPO(Pinned) Pre-terminated Trunk Cable, MPO12, 72-Fiber, LSZH, 12 fiber PmP 2.0 mm /B2ca

## Product Classification

<b>Regional Availability</b>	Europe
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber trunk cable assembly
<b>Product Brand</b>	SYSTIMAX ULL
<b>Ordering Note</b>	Not available in the United States or Canada

## General Specifications


<b>Color, boot A</b>	Black
<b>Color, connector A</b>	Lime green
<b>Color, boot B</b>	Black
<b>Color, connector B</b>	Lime green
<b>Construction Type</b>	Stranded
<b>Furcation Color</b>	Lime green
<b>Interface, Connector A</b>	MPO-12/UPC Male
<b>Interface, Connector B</b>	MPO-12/UPC Male
<b>Jacket Color</b>	Lime green
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Fibers per Subunit, quantity</b>	12
<b>Total Fibers, quantity</b>	72

# U3VMXMxAk

## Dimensions

<b>Breakout Length</b>	33 in
<b>Cable Assembly Length Range (m)</b>	3 – 999
<b>Cable Assembly Length Range (ft)</b>	10 – 999

## Ordering Tree

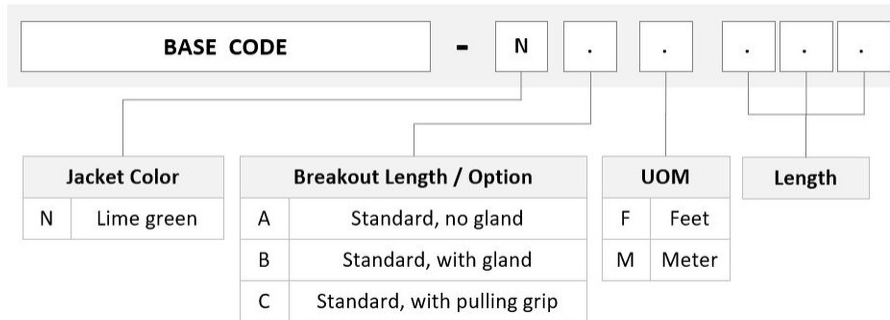

## Mechanical Specifications

<b>Cable Retention Strength, maximum</b>	11.24 lb @ 0 °   4.40 lb @ 90 °
--	---------------------------------

## Optical Specifications

<b>Fiber Mode</b>	Multimode
<b>Fiber Type</b>	OM5, LazrSPEED®

## Environmental Specifications

<b>Operating Temperature</b>	-10 °C to +60 °C (+14 °F to +140 °F)
<b>Environmental Space</b>	Indoor   Low Smoke Zero Halogen (LSZH)

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

# U3VMXMXAK

---



## Included Products

- 760239609  
N-072-MP-5G-F12LM/B2 - Fiber indoor cable, LazrSPEED®, Low Smoke Zero Halogen Riser MPO Trunk, 72 fiber, 12 fiber subunits, Multimode OM5, Gel-free, Feet jacket marking, Lime green jacket color, B2ca Flame rating
- 860617240 - MPO12, ULTRA LOW LOSS, MALE, OM5, LIME, 3mm