


# U4XMPLCAL

## Base Product

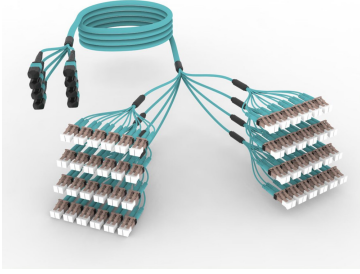

Ultra Low Loss OM4 MPO12 Unpinned to LC/UPC 96-Fiber InstaPATCH® 360 Ruggedized Fanout Cable, Low Smoke Zero Halogen

**This product will be discontinued on: April 30, 2024**

**Replaced By:**

U4XMPLCCL

Ultra Low Loss ULL LazrSPEED® 550 MPO(Unpinned) to LC/UPC Ruggedized fanout Cable, 96-Fiber, LSZH, 12 fiber PmP 2.0 mm /B2ca

## Product Classification

<b>Regional Availability</b>	Europe
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Ruggedized fanout
<b>Product Brand</b>	SYSTIMAX InstaPATCH® 360
<b>Ordering Note</b>	For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration   Not available in the United States or Canada

## General Specifications

<b>Color, boot A</b>	Black
<b>Color, connector A</b>	Aqua
<b>Color, boot B</b>	Aqua
<b>Color, connector B</b>	Beige
<b>Construction Type</b>	Stranded
<b>Furcation Color</b>	Aqua
<b>Interface, Connector A</b>	MPO-12/UPC Female
<b>Interface, Connector B</b>	LC/UPC
<b>Jacket Color</b>	Aqua
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Fibers per Subunit, quantity</b>	12
<b>Total Fibers, quantity</b>	96


# U4XMPLCAL

## Dimensions

**Cable Assembly Length Range (m)** 3 – 999

**Cable Assembly Length Range (ft)** 7 – 999

## Ordering Tree

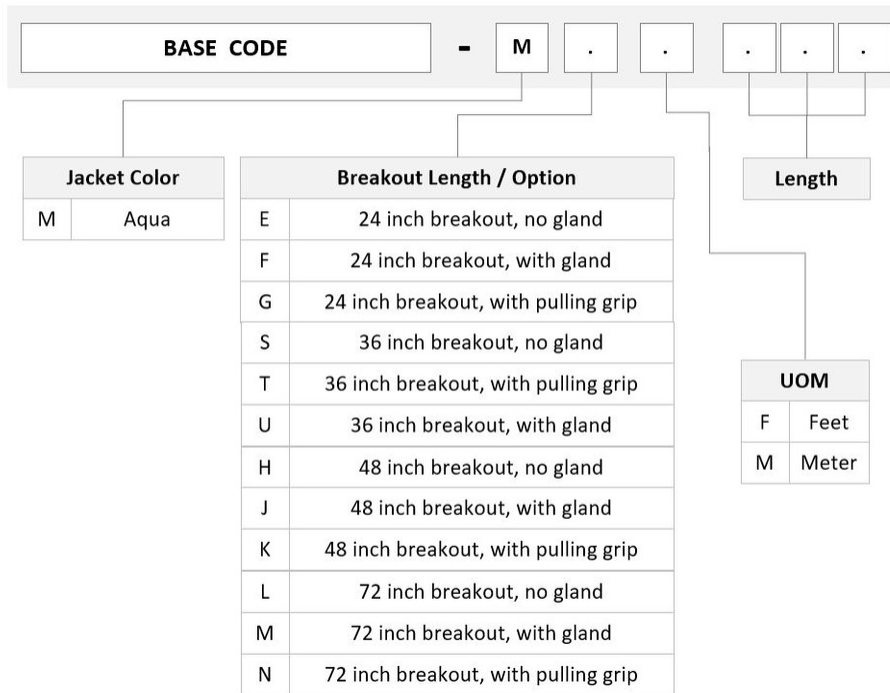

## Optical Specifications

**Fiber Mode** Multimode

**Fiber Type** OM4, LazrSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Indoor | Low Smoke Zero Halogen (LSZH)

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
ANATEL	Compliant

# U4XMPLCAL

---

CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant



## Included Products

760239603 N-096-MP-5K-F12AQ/B2	-	Fiber indoor cable, LazrSPEED®, Low Smoke Zero Halogen Riser MPO Trunk, 96 fiber, 12 fiber subunits, Multimode OM4, Gel-free, Feet jacket marking, Aqua jacket color, B2ca Flame rating
860366210	-	MPO12, ULTRA LOW LOSS, FEMALE, OM3/4, AQUA, 3mm
860637378	-	LazrSPEED® Elite LC Connector duplex for 1.6 mm Fiber, multimode
CS-5K-MP	-	LazrSPEED® 550 OM4 Bend-Insensitive Multimode Fiber