


# UJXQXQXQH

## Base Product

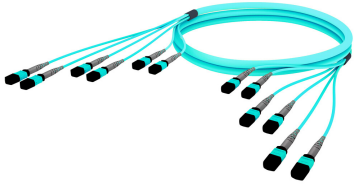

Ultra Low Loss (ULL) OM4 MPO8 QSFP (Pinned) to MPO8 QSFP (Pinned), Fiber Trunk Cable Assembly, 48-Fiber, Low Smoke Zero Halogen (LSZH)

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   Europe   Latin America   Middle East /Africa   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber trunk cable assembly
<b>Product Brand</b>	SYSTIMAX ULL
<b>Ordering Note</b>	Not available in the United States or Canada

## General Specifications

<b>Color, boot A</b>	Gray
<b>Color, connector A</b>	Aqua
<b>Color, boot B</b>	Gray
<b>Color, connector B</b>	Aqua
<b>Construction Type</b>	Stranded
<b>Furcation Color</b>	Aqua
<b>Interface, Connector A</b>	MPO-08/UPC Male
<b>Interface Feature, connector A</b>	QSFP configuration
<b>Interface, Connector B</b>	MPO-08/UPC Male
<b>Interface Feature, connector B</b>	QSFP configuration
<b>Jacket Color</b>	Aqua
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Fibers per Subunit, quantity</b>	8
<b>Total Fibers, quantity</b>	48

## Dimensions

<b>Breakout Length</b>	33 in
<b>Cable Assembly Length Range (m)</b>	3 – 999
<b>Cable Assembly Length Range (ft)</b>	10 – 999



# UJXQXQXQH

---

N-072-MP-5K-F12AQ/D

- Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 72 fiber multi-unit with 12 fiber subunits, Gel-free, Multimode OM4, Feet jacket marking, Aqua jacket color, Dca flame rating

860633308

- MPO8, ULTRA LOW LOSS, MALE, OM3/4, AQUA, 3m