


Base Product

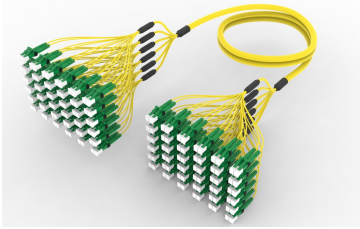

Ultra Low Loss ULL TeraSPEED® LC/APC G B to LC/APC G B
Ruggedized fanout Cable, 72-Fiber, LSZH, 12 fiber PmP 2.0 mm Dca

Product Classification

Regional Availability

Asia | Australia/New Zealand | Europe | Latin America | Middle East/Africa | North America

Portfolio

CommScope®

Product Type

Ruggedized fanout

Product Brand

SYSTIMAX ULL

Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative | For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

General Specifications

Color, boot A

Green

Color, connector A

Green

Color, boot B

Green

Color, connector B

Green

Construction Type

Stranded

Furcation Color

Yellow

Interface, Connector A

LC/APC

Interface Feature, connector A

Grade B performance

Interface, Connector B

LC/APC

Interface Feature, connector B

Grade B performance

Jacket Color

Yellow

Fibers per Subunit, quantity

12

Total Fibers, quantity

72

Dimensions

Cable Assembly Length Range (m)


3 – 305

Cable Assembly Length Range (ft)

10 – 999

UNGLGLGCK

Ordering Tree

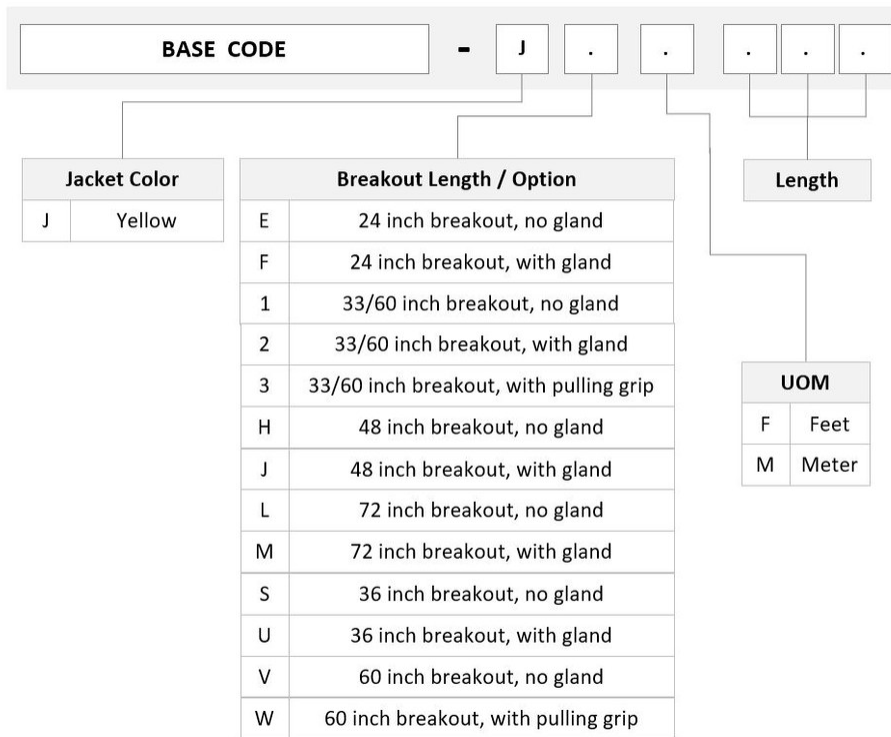

Optical Specifications

| | |
|-------------------|----------------------|
| Fiber Mode | Singlemode |
| Fiber Type | G.657.A2, TeraSPEED® |

Environmental Specifications

| | |
|-----------------------------------------------------|--------------------------------------|
| Operating Temperature | -10 °C to +60 °C (+14 °F to +140 °F) |
| EN50575 CPR Cable EuroClass Fire Performance | Dca |
| Environmental Space | Dual Rated LSZH/Riser Indoor |

Regulatory Compliance/Certifications

| Agency | Classification |
|---------------|--------------------------------------------------------------------------------|
| ANATEL | Compliant |
| CHINA-ROHS | Below maximum concentration value |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |

UNGLGLGCK

REACH-SVHC Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS Compliant

UK-ROHS Compliant



Included Products

- 760242311 N-072-MP-8G-F12YL/20T/D – Fiber indoor cable, Low Smoke Zero Halogen Riser MPO Trunk, 72 fiber multi-unit with 12 fiber 2.0 mm subunits, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color, Dca flame rating