


# URGQPLUHF

## Base Product

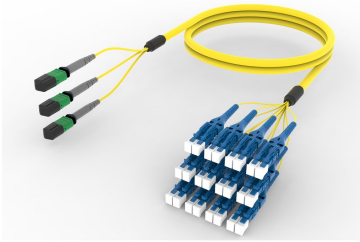

Ultra Low Loss Singlemode, MPO8 QSFP (Unpinned) to LC/UPC Uniboot, Fiber Extension Cable Assembly, 24-Fiber, Low Smoke Zero Halogen

## Product Classification

<b>Regional Availability</b>	Australia/New Zealand   Europe   Latin America   Middle East/Africa
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber array cable assembly
<b>Product Brand</b>	SYSTIMAX ULL
<b>Ordering Note</b>	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications

<b>Color, boot A</b>	Gray
<b>Color, connector A</b>	Green
<b>Color, boot B</b>	Blue
<b>Color, connector B</b>	Blue
<b>Construction Type</b>	Stranded
<b>Furcation Color</b>	Yellow
<b>Interface, Connector A</b>	MPO-08/APC Female
<b>Interface Feature, connector A</b>	QSFP configuration
<b>Interface, Connector B</b>	LC/UPC
<b>Interface Feature, connector B</b>	Uniboot
<b>Jacket Color</b>	Yellow
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Total Fibers, quantity</b>	24


## Dimensions

# URGQPLUHF

**Cable Assembly Length Range (m)** 1 – 305

**Cable Assembly Length Range (ft)** 3 – 999

## Ordering Tree

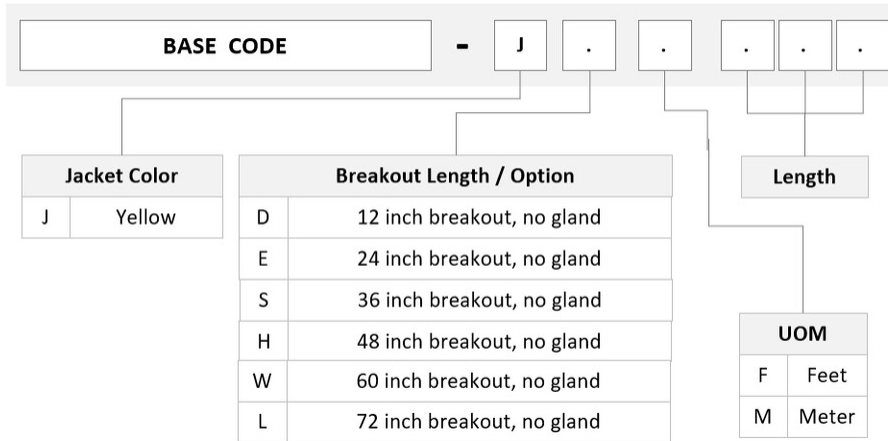

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0° | 4.40 lb @ 90°

## Optical Specifications

**Fiber Mode** Singlemode

**Fiber Type** G.657.A2, TeraSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Indoor | Low Smoke Zero Halogen (LSZH)

## Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted

# URGQPLUHF

---

UK-ROHS

Compliant/Exempted



## Included Products

- 760238097 N-024-MP-8G-F36YL/D – Low Smoke Zero Halogen Riser Light Duty MPO Patchcord Cable, 24 fiber
- 860637706 – MPO8, ULTRA LOW LOSS, FEMALE, Singlemode, GREEN, 3mm
- 860650412 – TeraSPEED® LC UniBoot 2.0MM UPC/LC UNIBOOT CONNECTOR KIT