


# URXQXQXHF

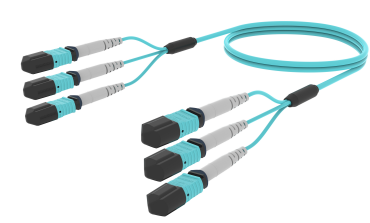

Ultra Low Loss (ULL) LazrSPEED® 550 OM4, MPO/8 (Pinned) to MPO/8 (Pinned), 24-Fiber, LSZH array cord

## Product Classification

|                       |  |
|-----------------------|--|
| Regional Availability | Asia   Australia/New Zealand   Europe   Latin America   Middle East /Africa   North America  |
| Portfolio             | CommScope®   |
| Product Type          | Fiber array cable assembly   |
| Product Brand         | SYSTIMAX ULL   |
| Ordering Note         | For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration |

## General Specifications


|                              |                         |
|------------------------------|-------------------------|
| Color, boot A                | Gray                    |
| Color, connector A           | Aqua                    |
| Color, boot B                | Gray                    |
| Color, connector B           | Aqua                    |
| Construction Type            | Stranded                |
| Furcation Color              | Aqua                    |
| Interface, Connector A       | MPO-08/UPC Male         |
| Interface, Connector B       | MPO-08/UPC Male         |
| Jacket Color                 | Aqua                    |
| Polarity                     | Method B Enhanced (ULL) |
| Fibers per Subunit, quantity | 8                       |
| Total Fibers, quantity       | 24                      |

## Dimensions

|                                  |         |
|----------------------------------|---------|
| Cable Assembly Length Range (m)  | 1 – 305 |
| Cable Assembly Length Range (ft) | 1 – 999 |

## Ordering Tree

# URXQXQXHF

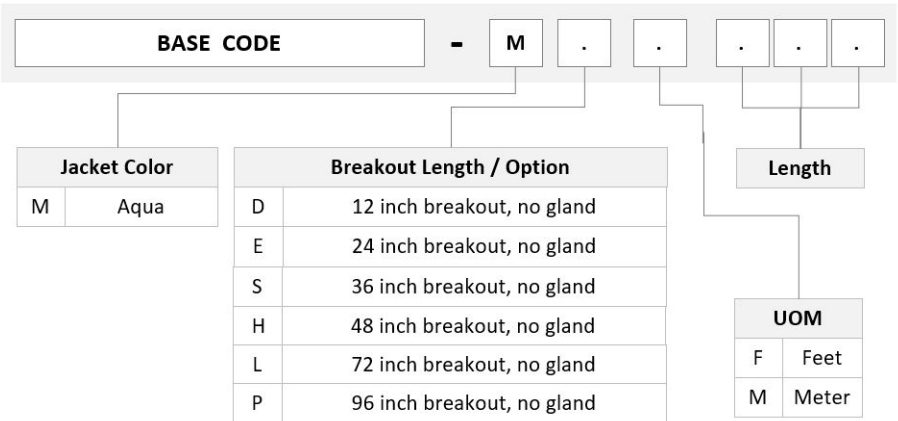

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

**Fiber Mode** Multimode  
**Fiber Type** OM4, LazrSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)  
**Environmental Space** Indoor | Low Smoke Zero Halogen (LSZH)

## Regulatory Compliance/Certifications

| Agency        | Classification   |
|---------------|--|
| ANATEL        | Compliant  |
| CHINA-ROHS    | Above maximum concentration value  |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system   |
| REACH-SVHC    | Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS          | Compliant/Exempted   |
| UK-ROHS       | Compliant/Exempted   |



# URXQXQXHF

---

## Included Products

- |                                  |   |  |
|----------------------------------|---|--|
| 760161786<br>N-024-MP-5K-F36AQ/D | - | Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser Light Duty for MPO Patchcords, 24 fiber, Multimode OM4, Gel-free, Feet jacket marking, Aqua jacket color, Dca flame rating |
| 860633308                        | - | MPO8, ULTRA LOW LOSS, MALE, OM3/4, AQUA, 3m  |