


# AJGMXXMXAM

## Base Product

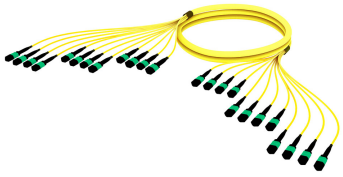

Singlemode MPO12 (Pinned) to MPO12 (Pinned), Fiber Trunk Cable Assembly, 144-Fiber, Method A, Low Smoke Zero Halogen

## Product Classification

|                              |  |
|------------------------------|--|
| <b>Regional Availability</b> | Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America               |
| <b>Portfolio</b>             | CommScope®   |
| <b>Product Type</b>          | Fiber trunk cable assembly   |
| <b>Ordering Note</b>         | For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration |

## General Specifications


|                                     |                 |
|-------------------------------------|-----------------|
| <b>Color, boot A</b>                | Black           |
| <b>Color, connector A</b>           | Green           |
| <b>Color, boot B</b>                | Black           |
| <b>Color, connector B</b>           | Green           |
| <b>Construction Type</b>            | Stranded        |
| <b>Furcation Color</b>              | Yellow          |
| <b>Interface, Connector A</b>       | MPO-12/APC Male |
| <b>Interface, Connector B</b>       | MPO-12/APC Male |
| <b>Jacket Color</b>                 | Yellow          |
| <b>Polarity</b>                     | Method A        |
| <b>Fibers per Subunit, quantity</b> | 12              |
| <b>Total Fibers, quantity</b>       | 144             |

## Dimensions

|   |          |
|---|----------|
| <b>Cable Assembly Length Range (m)</b>  | 3 – 999  |
| <b>Cable Assembly Length Range (ft)</b> | 10 – 999 |

## Ordering Tree

# AJGMXXMAM

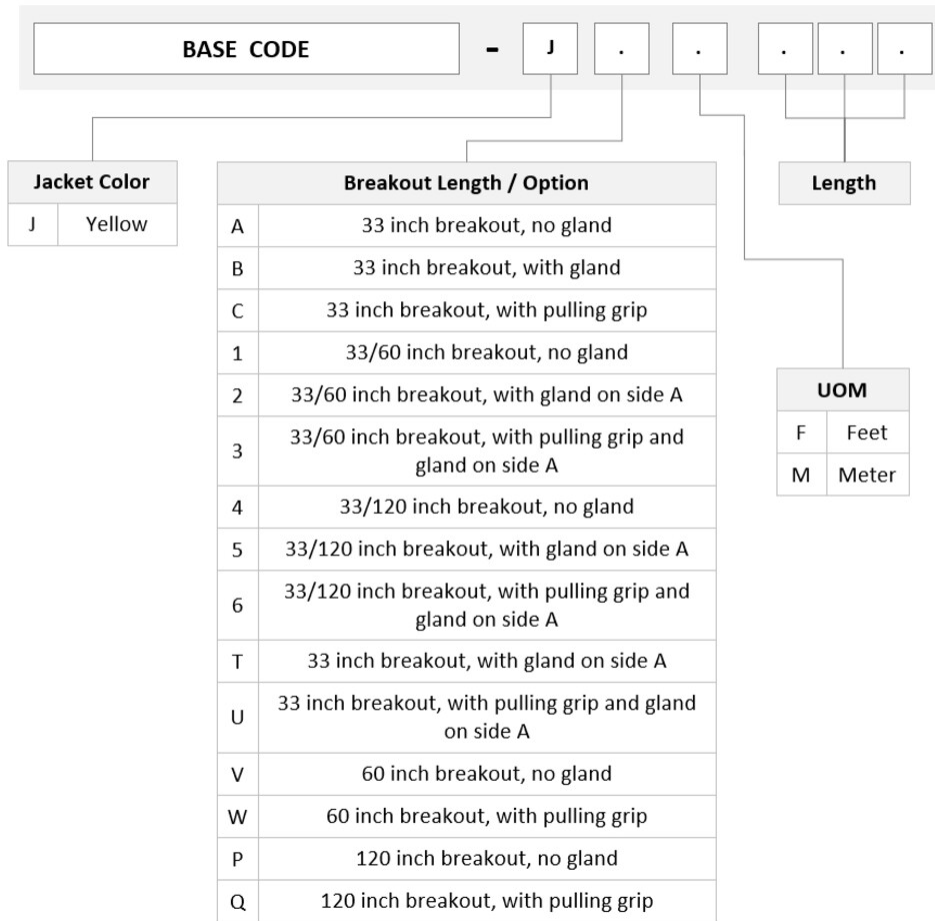

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

**Fiber Mode** Singlemode

**Fiber Type** G.652.D | G.657.A2, TeraSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Dual Rated LSZH/Riser | Indoor

## Regulatory Compliance/Certifications

**Agency**

**Classification**

# AJGMXMXAM

---

|               |  |
|---------------|--|
| ANATEL        | Compliant  |
| CHINA-ROHS    | Above maximum concentration value  |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system   |
| REACH-SVHC    | Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS          | Compliant/Exempted   |
| UK-ROHS       | Compliant/Exempted   |



## Included Products

- 760237978  
N-144-MP-8G1-F12YL/D – Fiber indoor cable, Low Smoke Zero Halogen Riser MPO Trunk, 144 fiber multi-unit with 12 fiber subunits, Gel-free, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color, Dca flame rating
- 860638317 – MPO12, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 3mm