


CB9468-000 | OCJ-S3-03MASEN-S3

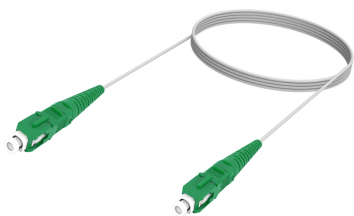

Fiber Optic Patch Cord, Simplex, Singlemode, SC/APC 9° to SC/APC 9°, white, 3 m

Product Classification

| | |
|------------------------------|---------------------------|
| Regional Availability | EMEA |
| Product Type | Fiber patch cord, simplex |
| Product Series | OCJ |

General Specifications

| | |
|---------------------------------------|--------|
| Connector A, quantity | 1 |
| Color, boot A | Green |
| Color, connector A | Green |
| Connector B, quantity | 1 |
| Color, boot B | Green |
| Color, connector B | Green |
| Interface, Connector A | SC/APC |
| Interface Feature, connector A | APC 9° |
| Interface, Connector B | SC/APC |
| Interface Feature, connector B | APC 9° |
| Jacket Color | White |
| Total Fibers, quantity | 1 |

Dimensions

| | |
|---|-------------------|
| Cable Assembly Length Range (m) | 1 – 999 |
| Cable Assembly Length Range (ft) | 1 – 999 |
| Cord Length | 3 m 9.843 ft |
| Diameter Over Jacket | 0.9 mm 0.035 in |

Optical Specifications

| | |
|-------------------|----------------------|
| Fiber Mode | Singlemode |
| Fiber Type | G.657.A1, TeraSPEED® |

CB9468-000 | OCJ-S3-03MASEN-S3

| | |
|---|------------------|
| Performance Grade | Standard C grade |
| Insertion Loss, maximum, connector A | 0.5 dB |
| Insertion Loss, maximum, connector B | 0.5 dB |
| Return Loss, minimum, connector A | 60 dB |
| Return Loss, minimum, connector B | 60 dB |

Environmental Specifications

| | |
|------------------------------|--------------------------------------|
| Operating Temperature | -40 °C to +70 °C (-40 °F to +158 °F) |
| Environmental Space | Low Smoke Zero Halogen (LSZH) |

Packaging and Weights

| | |
|---------------------------|---|
| Packaging quantity | 1 |
|---------------------------|---|

* Footnotes

| | |
|--------------------------|---|
| Performance Grade | Guarantee to meet IEC 61755-1 Random Mating requirement |
|--------------------------|---|