


FPCMY-SPSC-P-15M

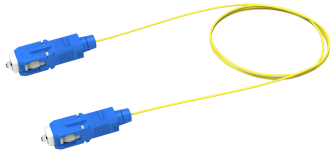

Fiber Optic Patch Cord, Simplex, Singlemode, SC/UPC to SC/UPC, yellow, 15 m

Product Classification

Regional Availability	Latin America North America
Product Type	Fiber patch cord, simplex
Product Series	FPCMY

General Specifications

Connector A, quantity	1
Color, boot A	Blue
Color, connector A	Blue
Connector B, quantity	1
Color, boot B	Blue
Color, connector B	Blue
Interface, Connector A	SC/UPC
Interface, Connector B	SC/UPC
Jacket Color	Yellow
Total Fibers, quantity	1

Dimensions

Cord Length	15 m 49.213 ft
Diameter Over Jacket	1.7 mm 0.067 in

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A2, TeraSPEED®
Insertion Loss, maximum, connector A	0.2 dB
Insertion Loss, maximum, connector B	0.2 dB
Return Loss, minimum, connector A	55 dB
Return Loss, minimum, connector B	55 dB

FPCMY-SPSC-P-15M

Environmental Specifications

Environmental Space Plenum

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

