


760005306 | M81-RCA-110-246-W

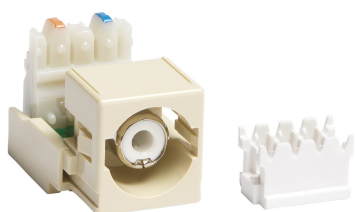

M81 RCA to 110 Punchdown Module Audio and Video Adapter, ivory housing white connector

OBSOLETE

This product was discontinued on: August 23, 2018

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Multimedia outlet

General Specifications

Color	Ivory
Color, RCA	White
Mounting	Snap-in
UTP 110 Terminal Block	110 ohm

Electrical Specifications

Attenuation dc at Frequency, maximum	2 dB @ 5.5 MHz
Crosstalk @ Gain at Frequency	-60 dB @ 5.5 MHz
Impedance	75 ohm
Insulation Resistance, minimum	50 MOhm

Material Specifications

Material Type	High-impact, flame retardant, thermoplastic
----------------------	---

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Storage Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Relative Humidity	5%–95%, non-condensing
Flammability Rating	UL 94 V-0

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency

ISO 9001:2015

Classification

Designed, manufactured and/or distributed under this quality management system

