


EHD Singlemode, 24 port LC field term splice cassette

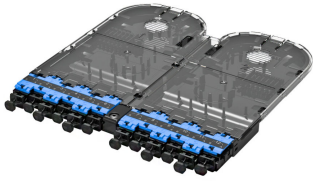

Product Classification

Regional Availability	North America
Portfolio	CommScope®
Product Type	Fiber cassette
Product Series	EHD

General Specifications

Color, front	Blue
Interface, front	LC/UPC
Interface, rear	No pigtail
Total Fibers, quantity	24

Dimensions

Height	11.43 mm 0.45 in
Width	169.672 mm 6.68 in
Depth	163.83 mm 6.45 in

Optical Specifications

Fiber Mode	Singlemode
-------------------	------------

Environmental Specifications

Safety Standard	CE CSA UL
------------------------	---------------

Packaging and Weights

Packaging quantity	1
---------------------------	---

Weight, net

0.159 kg | 0.35 lb

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Below maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant

