


# UHVMMXMXAL

Base Product

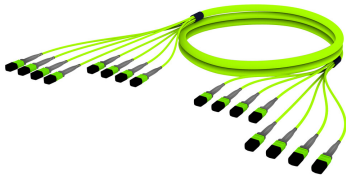

Ultra Low Loss (ULL) Multimode OM5 MPO12 (Pinned) to MPO12 (Pinned), Armored Pre-terminated Trunk Cable, 96-Fiber, Plenum

## OBSOLETE

This product was discontinued on: April 30, 2024

### Replaced By:

UHVMMXMXCL

Ultra Low Loss (ULL) OM5 MPO12 UPC (pinned) to MPO12 UPC (pinned) Fiber Trunk Cable Assembly, 96-Fiber, Armored Indoor Plenum

## Product Classification

### Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

### Portfolio

CommScope®

### Product Type

Fiber trunk cable assembly

### Product Brand

SYSTIMAX ULL

### Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative

## General Specifications

<b>Connector A, quantity</b>	8
<b>Color, boot A</b>	Black
<b>Color, connector A</b>	Lime green
<b>Connector B, quantity</b>	8
<b>Color, boot B</b>	Black
<b>Color, connector B</b>	Lime green
<b>Construction Type</b>	Armored   Stranded
<b>Furcation Color</b>	Lime green
<b>Interface, Connector A</b>	MPO-12/UPC Male
<b>Interface Feature, connector A</b>	Pinned
<b>Interface, Connector B</b>	MPO-12/UPC Male


# UHVMMXMXAL

<b>Interface Feature, connector B</b>	Pinned
<b>Jacket Color</b>	Lime green
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Fibers per Subunit, quantity</b>	12
<b>Total Fibers, quantity</b>	96

## Dimensions

<b>Breakout Length</b>	33 in
<b>Cable Assembly Length Range (m)</b>	3 – 999
<b>Cable Assembly Length Range (ft)</b>	10 – 999

## Ordering Tree

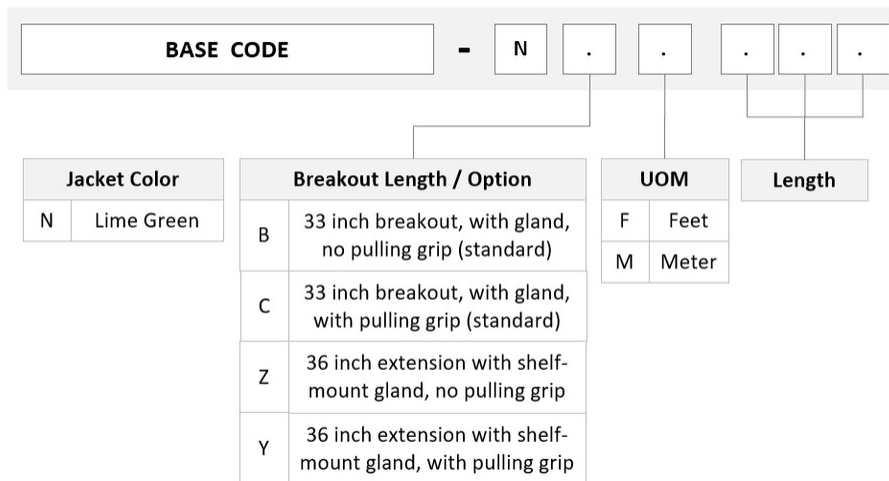

## Mechanical Specifications

<b>Cable Retention Strength, maximum</b>	11.24 lb @ 0°   4.40 lb @ 90°
--	-------------------------------

## Optical Specifications

<b>Fiber Mode</b>	Multimode
<b>Fiber Type</b>	OM5, LazrSPEED®

## Environmental Specifications

<b>Operating Temperature</b>	-10 °C to +60 °C (+14 °F to +140 °F)
------------------------------	--------------------------------------

# UHVMMXMXAL

Environmental Space

Indoor | Plenum

## Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



## Included Products

- |                                |   |   |
|--------------------------------|---|---|
| 760230250<br>P-096-MZ-5G-F12LM | - | Fiber indoor cable, LazrSPEED® Plenum MPO Trunk, interlocking aluminum armored with plenum jacket, Multimode OM5, 96 fiber multi-unit with 12 fiber subunits, Lime-green jacket color, Feet cable marking |
| 860617240                      | - | MPO12, ULTRA LOW LOSS, MALE, OM5, LIME, 3mm   |