


FACT-MMDC20R5UB-S

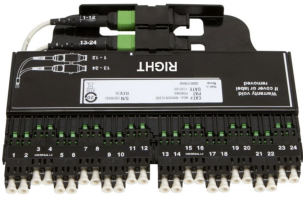

FACT® MPO Module, multimode, Ultra Low Loss (ULL), LC/UPC-MPO
24 fiber, right exit (for MPO module)

- Offers the same craft-friendly interface for LC and SC connectors as the cabled module
- Allow installers to connect an MPO trunk cable to turn up services in rapid installation applications

Product Classification

| | |
|------------------------------|-------------------------------|
| Regional Availability | Latin America North America |
| Portfolio | CommScope® |
| Product Type | Fiber module |
| Product Brand | FACT® |
| Product Series | FACT |

General Specifications

| | |
|-------------------------------------|-------------------------------|
| Functionality | Breakout |
| Application | For use with FACT panels |
| Adapter Color | Aqua |
| Adapters, quantity, front | 12 |
| Body Style | Duplex Straight orientation |
| Color, front | Black |
| Color, housing | Black |
| Color, rear | Black |
| Interface, front | LC/UPC |
| Interface, rear | MPO |
| Interface Feature, rear | Standard |
| Polarity | Pairs, straight |
| Total Ports, quantity, front | 24 |

Dimensions

| | |
|---------------|---------------------|
| Height | 13.21 mm 0.52 in |
| Width | 159.77 mm 6.29 in |

FACT-MMDC20R5UB-S

Depth 122.68 mm | 4.83 in

Optical Specifications

Fiber Mode Multimode

Fiber Type OM5, LazrSPEED® wideband

Environmental Specifications

Operating Temperature -5 °C to +40 °C (+23 °F to +104 °F)

Storage Temperature -5 °C to +50 °C (+23 °F to +122 °F)

Relative Humidity Up to 85%, non-condensing

Packaging and Weights

Packaging quantity 1

Packaging Type Bag | Carton

Regulatory Compliance/Certifications

| Agency | Classification |
|---------------|--|
| CHINA-ROHS | Above maximum concentration value |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |
| ROHS | Compliant/Exempted |
| UK-ROHS | Compliant/Exempted |

